

SPECIFICATIONS:

ELECTRICAL LIFE: 30,000 make-and-break cycles at full load.

CONTACT RESISTANCE: 20mΩ max. initial @2-4VDC 100mA for both silver and gold plated contacts.

INSULATION RESISTANCE: 1,000MΩ min.

DIELECTRIC STRENGTH: 1,500V RMS @ sea level.

OPERATING TEMPERATURE: -30°C to +85°C

MATERIALS:

CASE: Diallyl phthalate (DAP)(UL 94V-0).

TOGGLE HANDLE: Brass, chrome plated.

BUSHING: Brass, nickel plated.


HOUSING: Stainless steel.

SWITCH SUPPORT: Brass, tin plated.

TERMINAL SEAL: Epoxy.



Art. Nr.

RND 210-00471

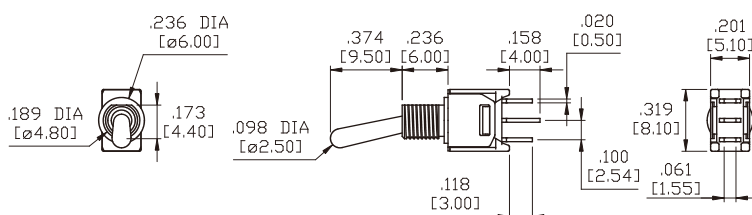


BUSHING

  THD




TERMINATION

PC THRU-HOLE

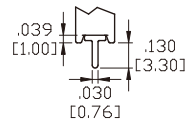


THK .020 [0.50]

ACTUATOR

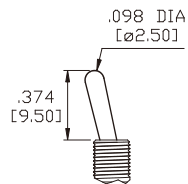

HARDWARE

NUT

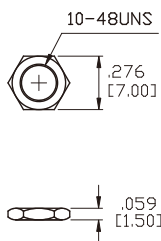

LOCK WASHER

