


# Sub-Miniature Slide Switch



## Specification

Contact Material	Phosphor Bronze, Gold Plated Over Nickel Plated
Terminal Material	Phosphor Bronze, Gold Plated Over Nickel Plated
Contact Resistance	50 mOhm
Contact Configuration	SPDT
Contact Rating	0.4 VA max. @ 48 V max. (AC or DC)
Insulation Resistance	500 MOhm min. 250 VAC
Dielectric Strength	500 VAC for 1 Minute
Electrical Life	30000 Make and Break Cycles at Full Load
Operating Temperature Min.	-20 °C
Operating Temperature Max.	80 °C
Switch Function	On-Off-On
Actuator Material	PBT
Housing	SPCC
Termination Type	PC, Through-Hole
Case	PBT, UL94V-0

## Drawing

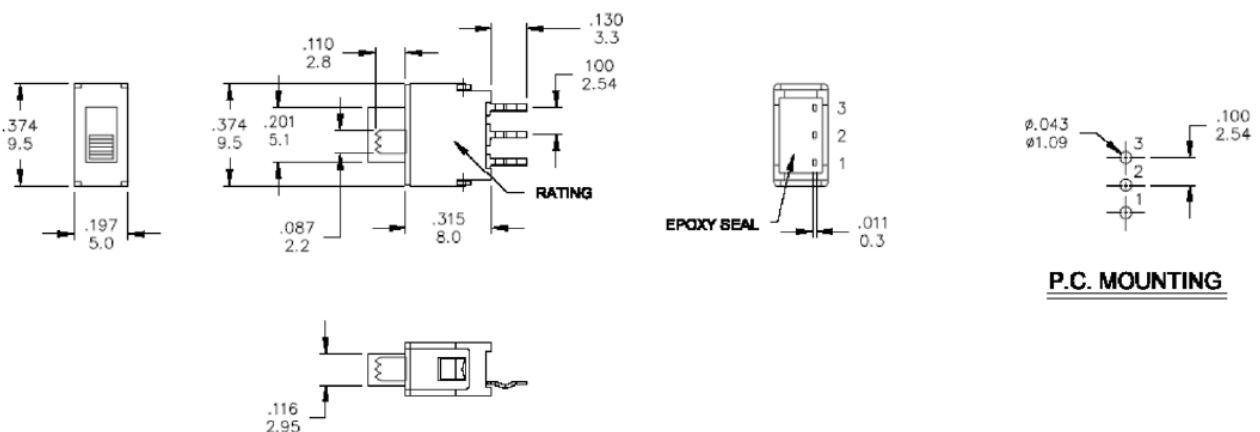

Art. Nr.  
RND 210-00596