


# Miniature Slide Switch



## Specification

Contact Material	Copper Alloy, Silver Plated
Terminal Material	Copper Alloy, Silver Plated
Contact Resistance	50 mOhm
Contact Configuration	DPDT
Contact Rating	1 A @ 250 VAC
Insulation Resistance	1000 MOhm min.
Dielectric Strength	1000 V RMS
Electrical Life	10000 Make and Break Cycles at Full Load
Operating Temperature Min.	-30 °C
Operating Temperature Max.	85 °C
Switch Function	ON-ON
Termination Type	PC

## Drawing

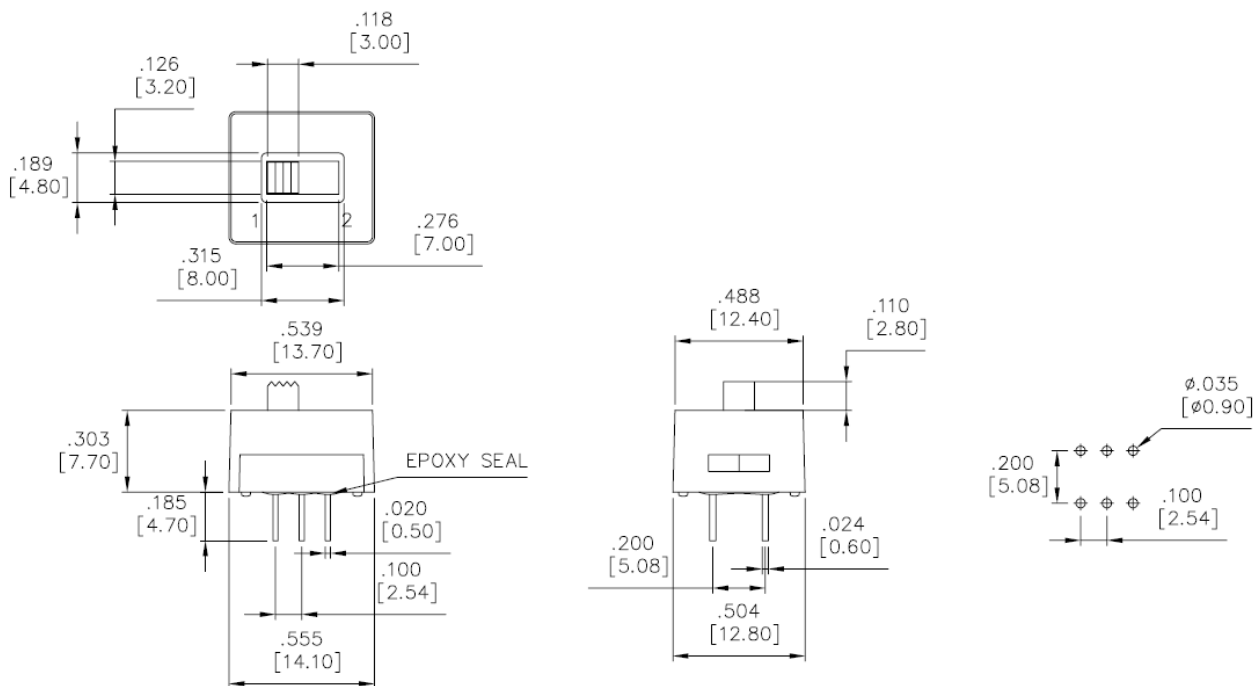

Art. Nr.  
RND 210-00600