



Low Power Slide Switch

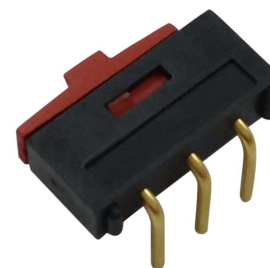

Specification

Contact Rating	0.5 A, 12 VDC; 0.3 A, 24 VDC
Terminal Material	Brass, Gold Over Nickel Plated
Contact Resistance	30 mOhm
Contact Configuration	SPDT
Housing Material	Nylon 6/6 (UL94V-0)
Insulation Resistance	5000 MOhm min. @ 500 VDC
Operating Force	800 gf
Mechanical Life	10000 Cycles
Switch Function	ON-ON
Termination Type	PC, Through Hole, Right Angle
Soldering Condition	Max. 5 sec @ 270 °C

Drawing

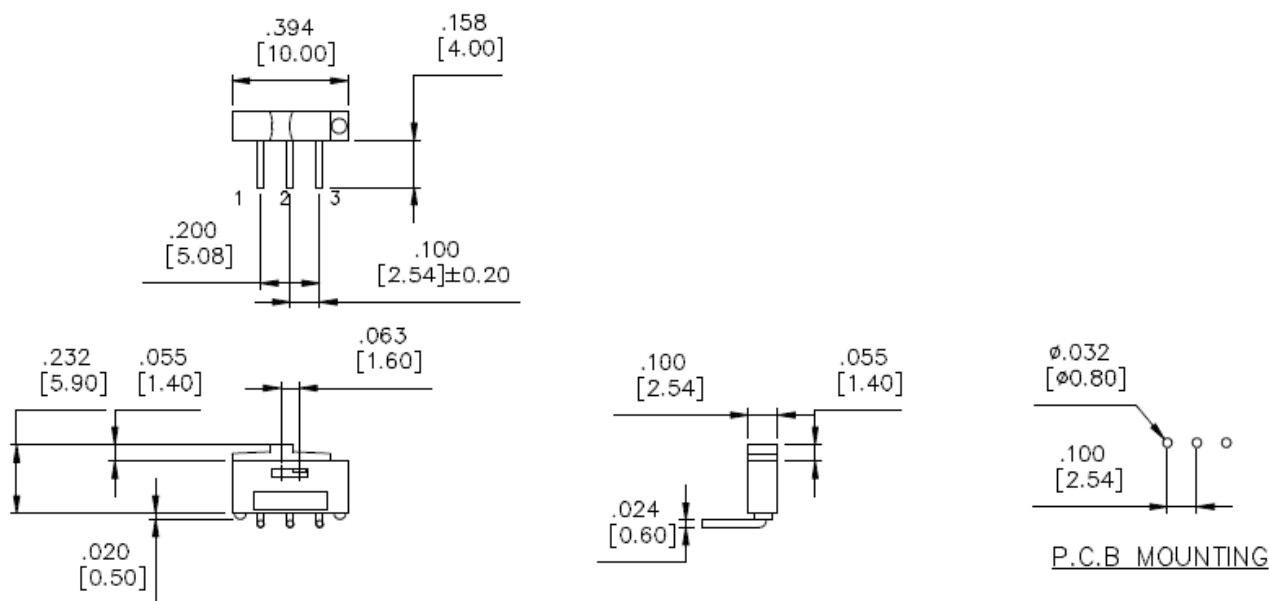

Art. Nr.
RND 210-00602