

# Miniature Toggle Switch




## Specification

Contact Configuration	1CO
Contact Rating	5 A @ 125 VAC or 28 VDC, 2 A @ 250 VAC
Electrical Life	50000 Make and Break Cycles at Full Load
Insulation Resistance	1 GOhm min.
Contact Resistance	10 mOhm max initial. @ 2 ... 4 VDC
Dielectric Strength	1.5 kV RMS @ Sea Level
Operating Temperature	-30 ... 85 °C
Switching Function	ON-OFF-ON
Actuator Height	10.4 mm
Termination Type	Solder Lug
Bushing	9 mm High, Keyway

## Material Specification

Contact Material	Silver
Terminal Plating Material	Silver
Case Material	Diallyl Phthalate, UL94V-0
Toggle Handle Material	Brass Chrome Plated
Bushing Material	Brass, Nickel Plated
Switch Support Material	Brass, Tin Plated
Housing Material	Stainless Steel

## Drawing

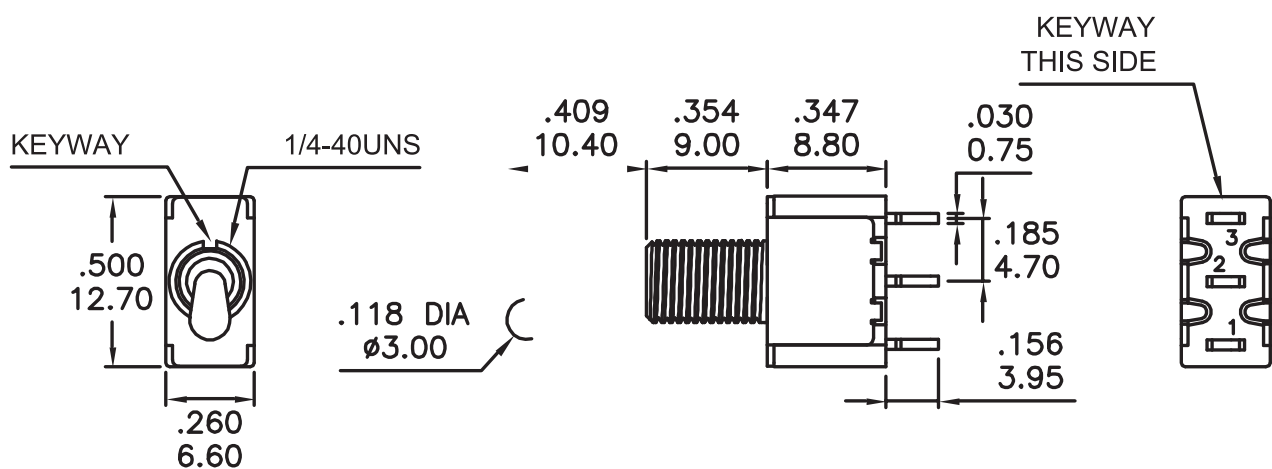

Art Nr.  
RND 210-00664