

Toggle Switch



Specification


Switch Rating	5 A @ 120 VAC or 28 VDC; 2 A @ 250 VAC
Contact Resistance	10 m Ω
Insulation Resistance	1 G Ω
Dielectric Strength	1,000 V RMS @ sea level
Operating Temperature	-40 °C ~ 85 °C
Mechanical Life	40,000
Position	3
Bushing Thread	1/4" -40 UNS

Material

Actuator	Brass, Chrome Plated
Bushing	Brass, Nickel Plated
House	Stainless Steel
Terminal/Contact	Silver Plated


Art. Nr.
RND 210-00836

Drawing

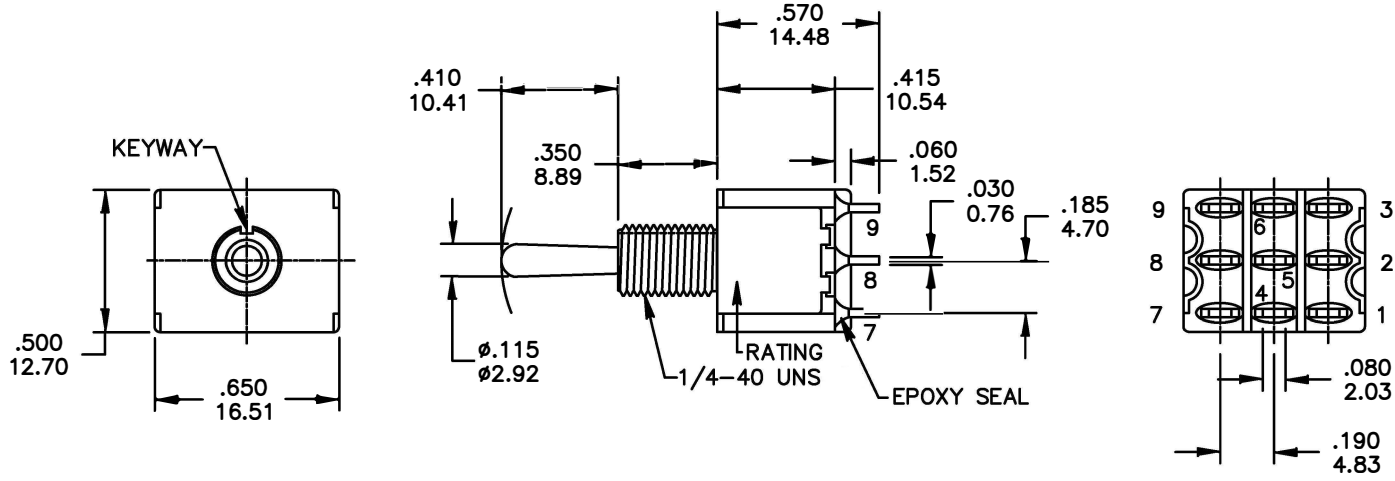


SWITCH FUNCTION

	POS.1	POS.2	POS.3
	ON	OFF	ON
Term. Comm.	2-3,5-6,8-9		2-1,5-4,8-7
SCHMATIC		OPEN	

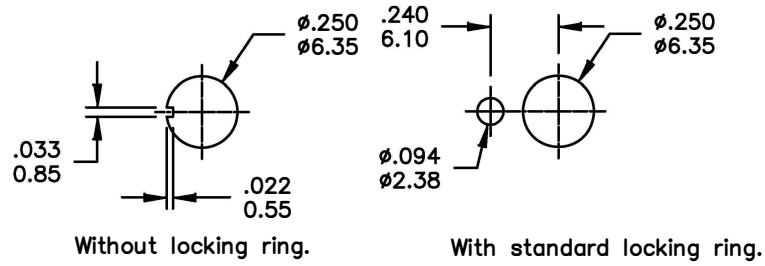

PANEL MOUNTING

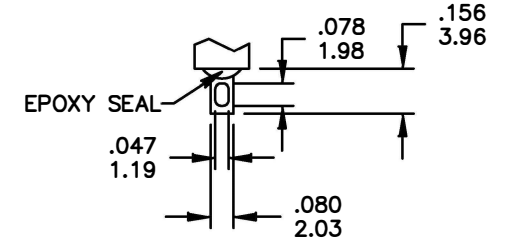

SOLDER LUG

Art. Nr.
RND 210-00836