

Specification


Switch Rating	5 A @ 120 VAC or 28 VDC; 2 A @ 250 VAC
Contact Resistance	10 mΩ
Insulation Resistance	1 GΩ
Dielectric Strength	1,000 V RMS @ sea level
Operating Temperature	-40 °C ~ 85 °C
Mechanical Life	40,000
Position	3
Bushing Thread	1/4" -40 UNS

Material

Actuator	Brass, Chrome Plated
Bushing	Brass, Nickel Plated
House	Stainless Steel
Terminal/Contact	Silver Plated

Art. Nr.
RND 210-00838

Drawing

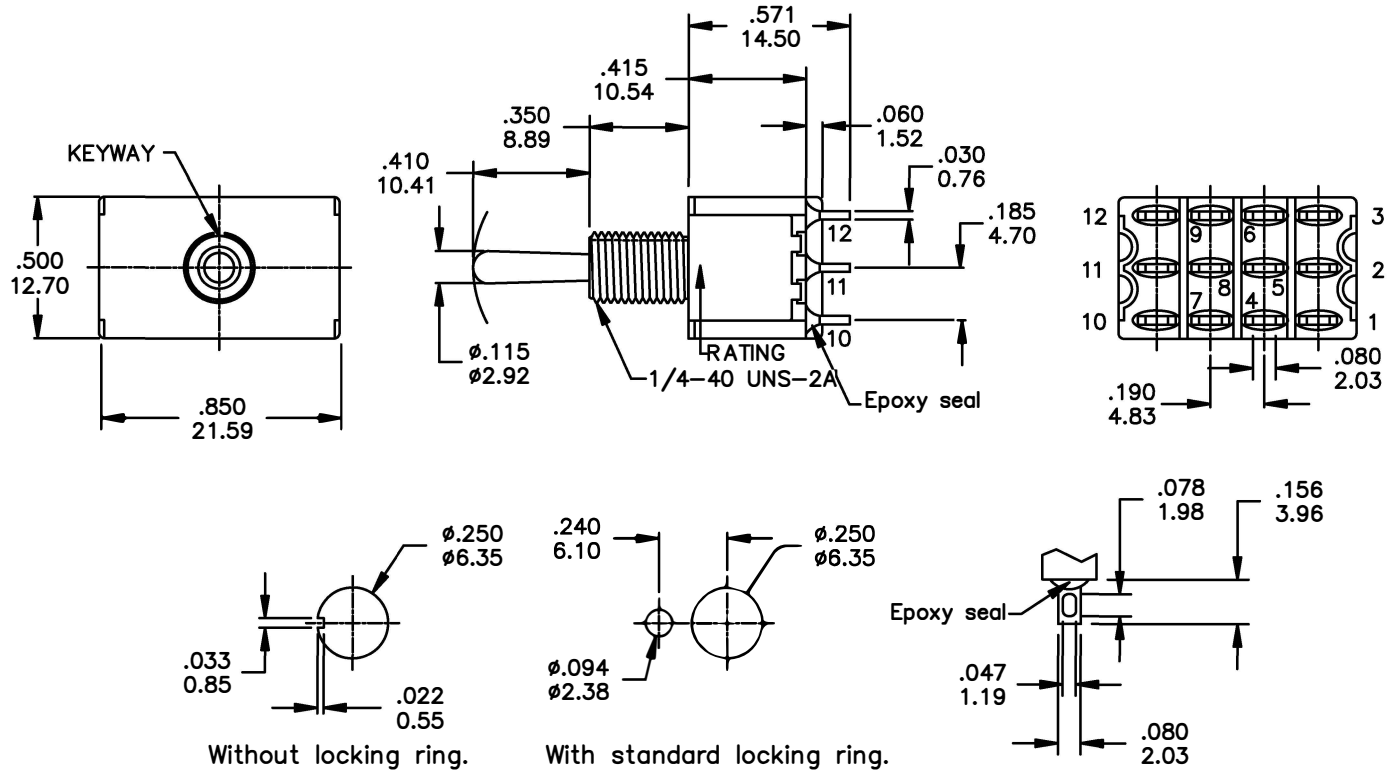

PANEL MOUNTING

SOLDER LUG

SWITCH FUNCTION

	POS.1	POS.2	POS.3
4P3	ON	OFF	ON
Term. Comm.	2-3,5-6 8-9,11-12		2-1,5-4 8-7,11-10
SCHEMATIC	OPEN		

HARDWARE

	PART NAME	Q'TY
1	1/4 INCH NUTS	2
2	LOCKING RING	1
3	LOCKING WASHER	1

Art. Nr.
RND 210-00838