


Toggle Switch



Switch Rating	3 A @ 125 VAC or 28 VDC ; 1.5 A @ 250 VAC
Movable Contact	Copper alloy, silver plated
Terminals	Copper alloy, silver plated
Contact Resistance	20 mΩ
Insulation Resistance	1 GΩ
Dielectric Strength	1500 V RMS @ sea level
Electrical Life	30,000
Operating Temperature	-30 °C ~ 85 °C
Position	3

Art. Nr.
RND 210-00842

Drawing

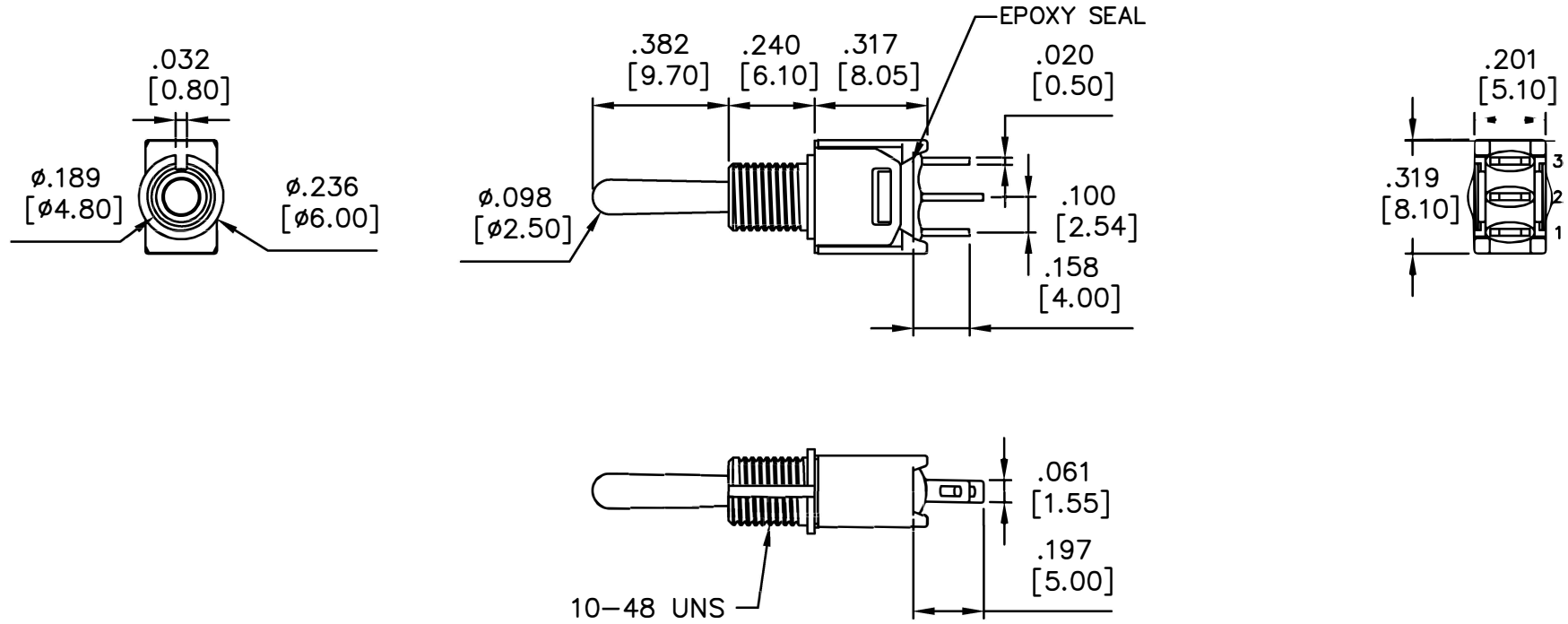

Art. Nr.
RND 210-00842