


Breadboard

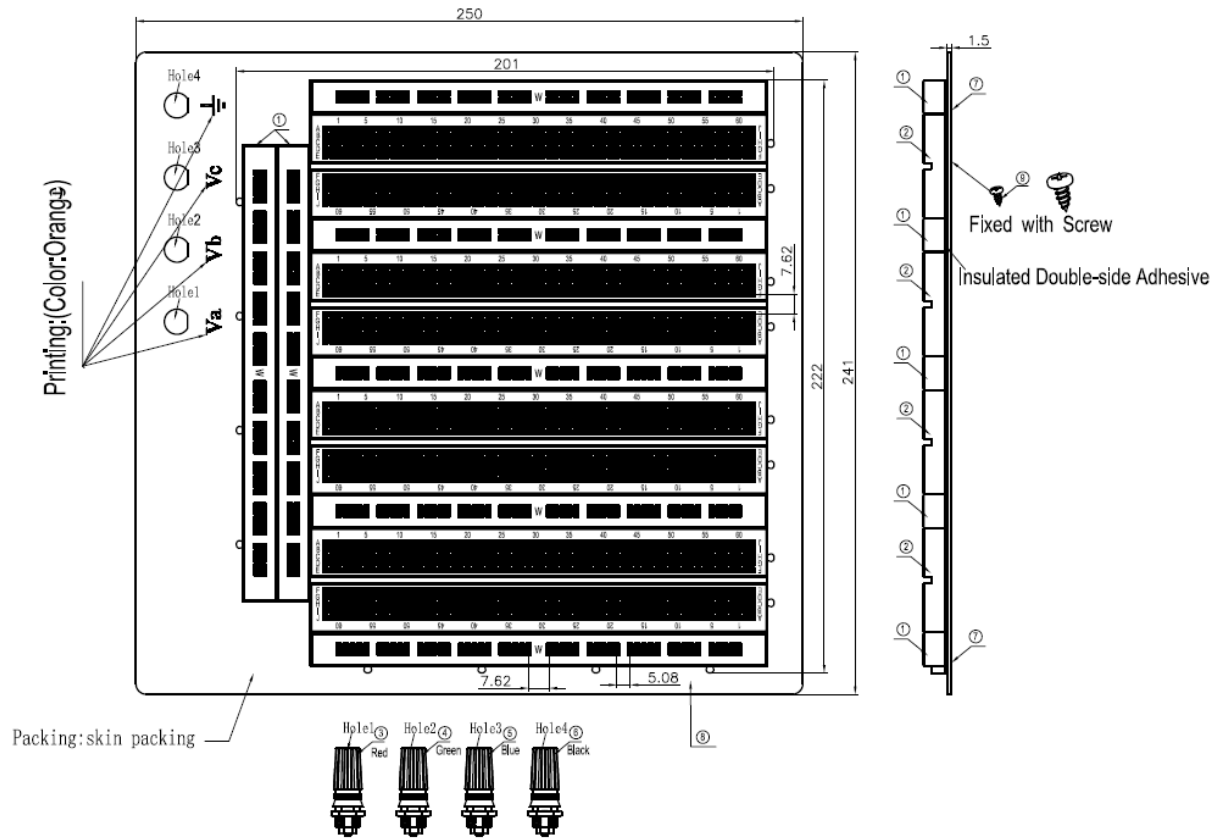


SPECIFICATIONS:

Pitch	2.54 mm
4 Terminal strips	2560 tie-point
7 Distribution strips	700 tie-point
Rated voltage/current	300 V / 3-5 A
Insulation resistance	500 MΩ / DC 500 V
Withstand voltage	AC 1000 V / 1 min
Wire range	28-20 AWG
Temp. range	-25°C ~ 80°C
Strip length	7-8 mm

TOLERANCES EXCEPT AS NOTED

variable range	linear dimension				fillet	chamfer	short angle sid				≡	-	□	//	⊥		
	to 6	over 6 to 30	over 30 to 120	over 120 to 480			to 6	to 10	to 50	to 120						to 5	to 30
tolerance	±0.1	±0.2	±0.3	±0.5	±0.9	±0.2	±0.5	±1	1°	30'	20'	10'	0.5	0.025	0.06	0.12	0.4

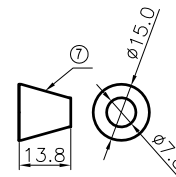

NO.	QTY	MATERIAL	NOTES
9	14	Steel	Black Zn
8	1	AL	Black paint
7	4	Rubber	UL94 V-2
6	1		Black Binding Post
5	1		Blue Binding Post
4	1		Green Binding Post
3	1		Red Binding Post
2	4		Terminal Strips
1	7		Distribution Strips

Art. Nr.

RND 255-00002