
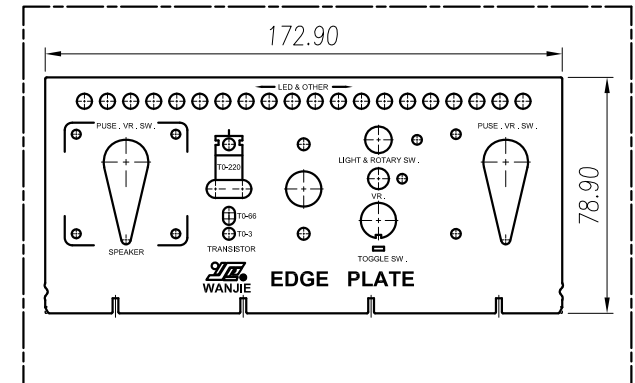
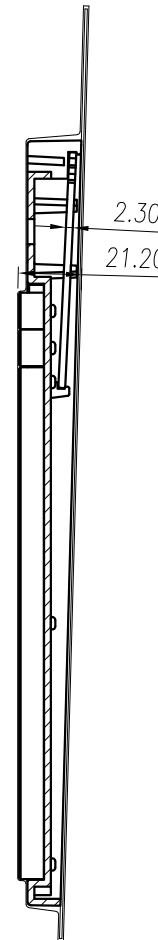


Breadboard

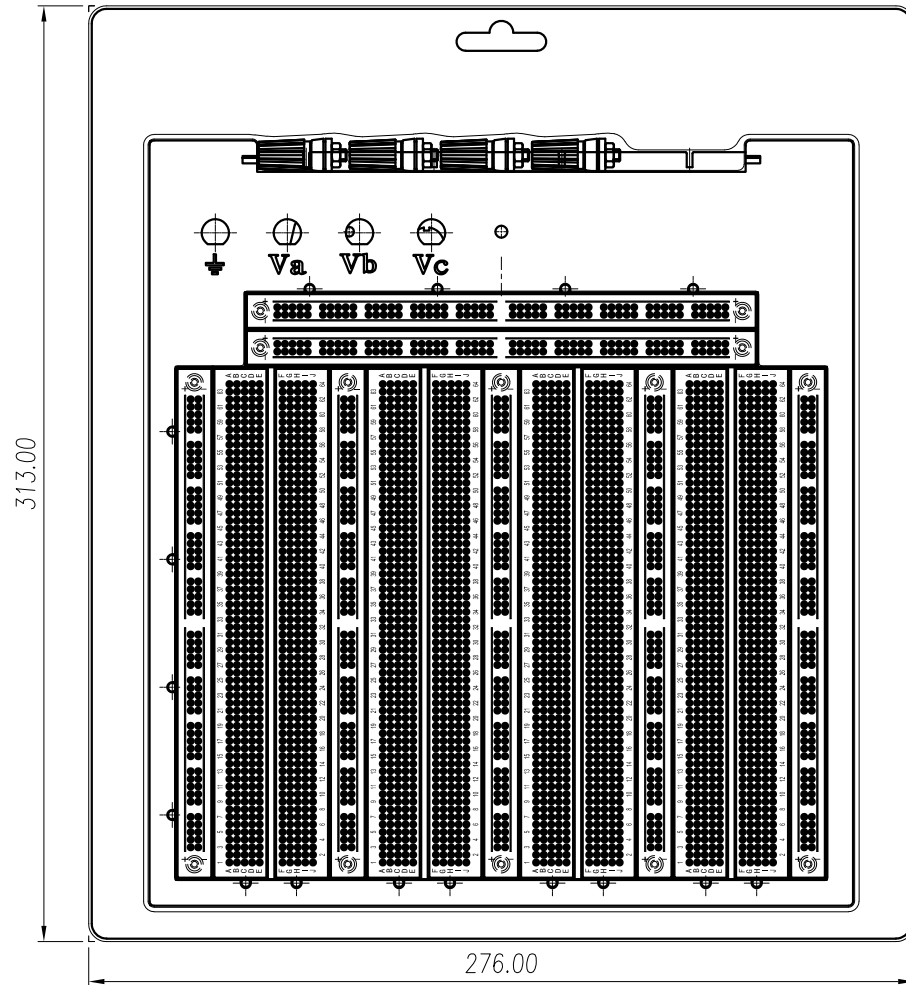

SPECIFICATIONS:

Pitch	2.54 mm
4 Terminal strips	2560 tie-point
7 Distribution strips	700 tie-point
Rated voltage/current	300 V / 3-5 A
Insulation resistance	500 MΩ / DC 500 V
Withstand voltage	AC 1000 V / 1 min
Wire range	28-20 AWG
Temp. range	-25°C ~ 80°C
Housing material	ABS plastic
Spring clips	Brass, Ni plated
Screws	M2.5 steel paint plated

Art. Nr.

RND 255-00003

		linear dimension (Tolerances Standard GB/T 14486-2008)										≡	—	□	//	⊥
variable range	to 6	over 6 to 10	over 10 to 18	over 18 to 30	over 30 to 50	over 50 to 80	over 80 to 120	over 120 to 160	over 160 to 200	over 200 to 250	over 250 to	all	to 5	over 5 to 30	over 30 to 120	over 120 to
	tolerance	±0.1	±0.14	±0.19	±0.25	±0.32	±0.43	±0.57	±0.72	±0.88	±1.05	±1.25	0.5	0.025	0.06	0.12