


Experimenting Plate




SPECIFICATIONS:

Pitch	2.54 mm
1 Terminal strip	640 tie-point
2 Distribution strips	200 tie-point
Rated voltage/current	300 V / 3-5 A
Insulation resistance	500 MΩ / DC 500 V
Withstand voltage	AC 1000 V / 1 min
Wire range	28-20 AWG
Strip length	7-8 mm
Temp. range	-25°C ~ 80°C

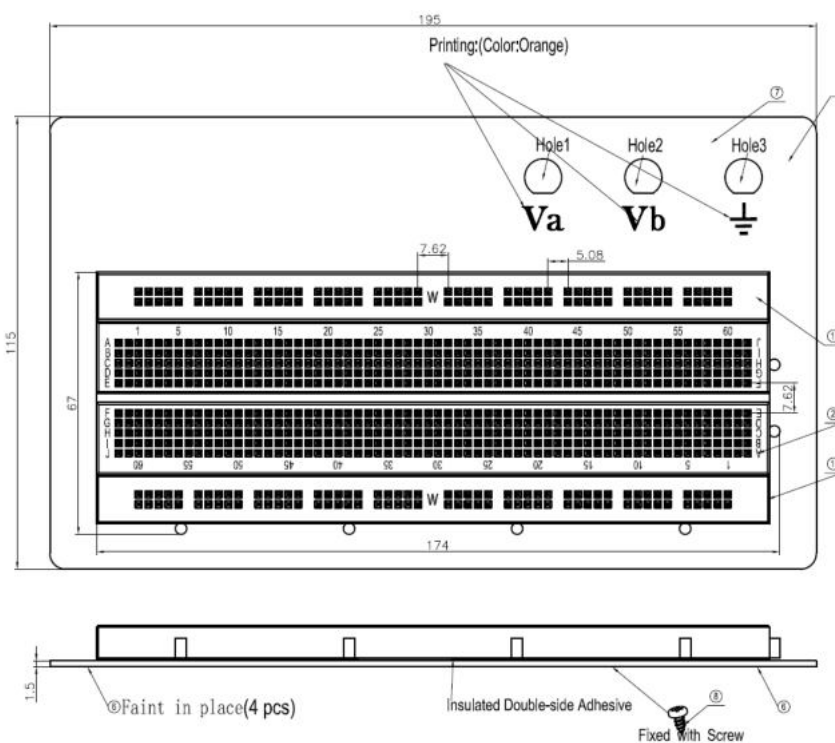

Packing: skin packing

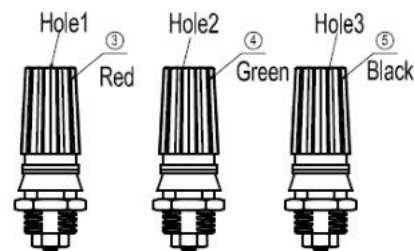

8	6	Steel	Black Zn
7	1	AL	Black paint
6	4	Rubber	UL94 V-2
5	1		Black Binding Post
4	1		Green Binding Post
3	1		Red Binding Post
2	1		Terminal Strip
1	2		Distribution Strips
NO.	Q' TY	MATERIAL	NOTES

TOLERANCES EXCEPT AS NOTED

variable range	linear dimension				fillet	chamfer		short angle sid				=	-	□	//	⊥	
	to 6	over 6 to 30	over 30 to 120	over 120 to 480		to 6	over 6 to 10	over 10 to 50	over 50 to 120	over 120 to 10'	all						to 5
tolerance	±0.1	±0.2	±0.3	±0.5	±0.9	±0.2	±0.5	±1	1'	30'	20'	10'	0.5	0.025	0.06	0.12	0.4

Art. Nr.

RND 255-00004