



# Experimenting Plate

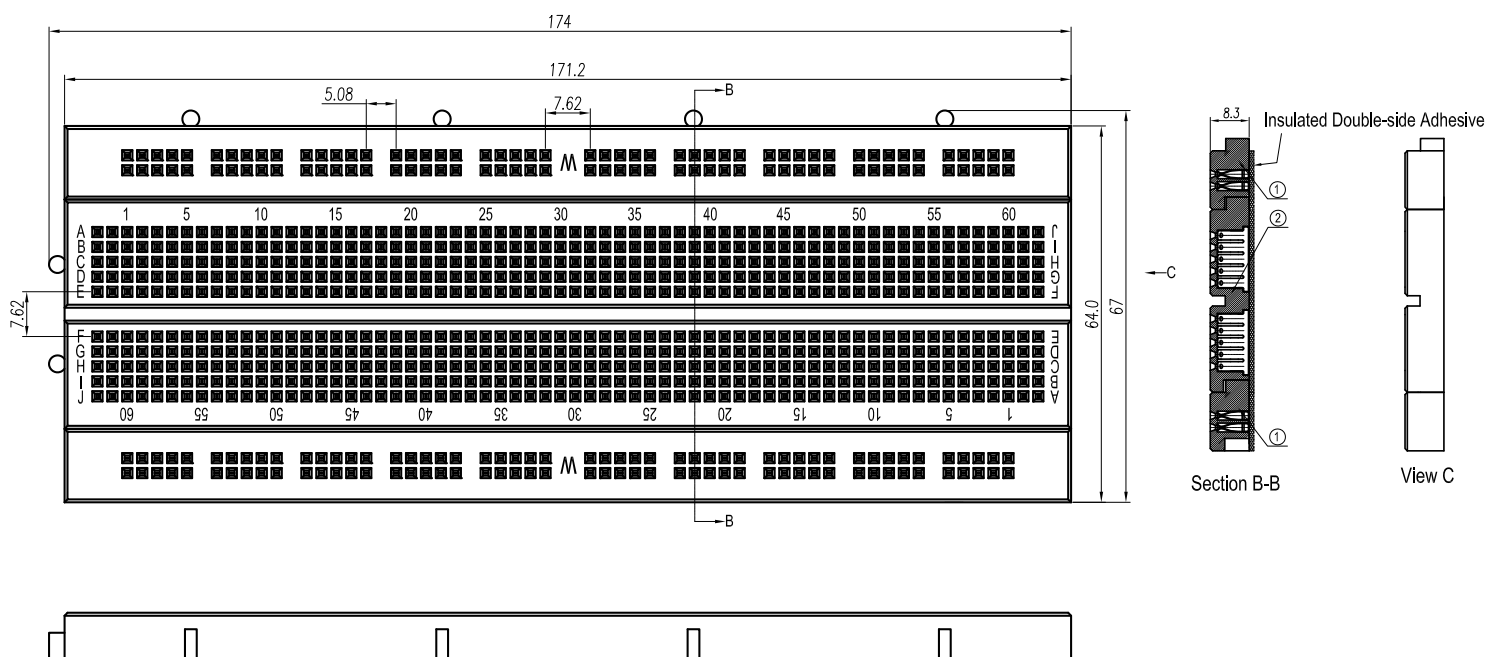

## SPECIFICATIONS:

Pitch	2.54 mm
1 Terminal strip	640 tie-point
2 Distribution strips	200 tie-point
Rated voltage/current	300 V / 3-5 A
Insulation resistance	500 MΩ / DC 500 V
Withstand voltage	AC 1000 V / 1 min
Wire range	28-20 AWG
Strip length	7-8 mm
Temp. range	-25°C ~ 80°C

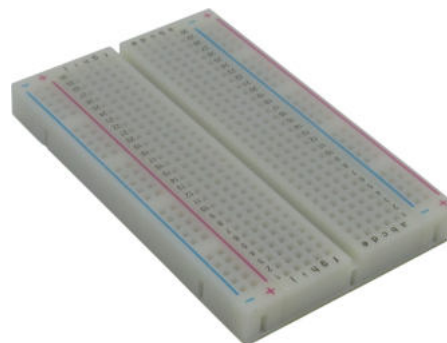

2	1	Terminal Strip
1	2	Distribution Strips
NO.	Q'TY	NOTES

## TOLERANCES EXCEPT AS NOTED

variable range	linear dimension				fillet	chamfer	short angle sid				=	-	□	//	⊥	
	to 6	over 6 to 30	over 30 to 120	over 120 to 480			all	to 6	over 6 to 10	over 10 to 50						over 50 to 120
tolerance	±0.1	±0.2	±0.3	±0.5	±0.2	±0.5	±1	1°	30'	20'	10'	0.5	0.025	0.06	0.12	0.4

Art. Nr.  
RND 255-00006