

Jumper Wire Kit (350 pcs)

SPECIFICATIONS:

350 pcs of 22 AWG solid wires

Per-cut, pre-stripped and pre-formed at each end

Completely reusable

Variety of colours



Included:

Jumper wire, 2 mm, bare wire (25 pcs)

Jumper wire, 5 mm, red (25 pcs)

Jumper wire, 7 mm, orange (25 pcs)

Jumper wire, 10 mm, yellow (25 pcs)

Jumper wire, 12 mm, green (25 pcs)

Jumper wire, 15 mm, blue (25 pcs)

Jumper wire, 17 mm, purple (25 pcs)

Jumper wire, 20 mm, grey (25 pcs)

Jumper wire, 22 mm, white (25 pcs)

Jumper wire, 25 mm, brown (25 pcs)

Jumper wire, 50 mm, red (25 pcs)



Jumper wire, 75 mm, orange (25 pcs)

Jumper wire, 100 mm, yellow (25 pcs)

Jumper wire, 125 mm, green (25 pcs)

Art. Nr.

RND 255-00007

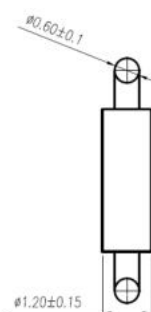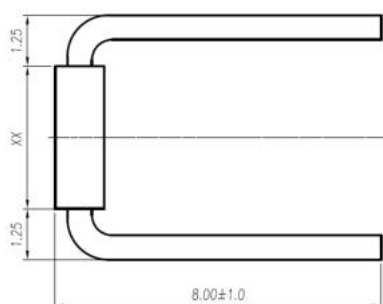

| | linear dimension (Tolerances Standard GB/T 14486-2008) | | | | | | | | | | | ≡ | — | □ | // | ⊥ |
|----------------|--|--------------|---------------|---------------|---------------|---------------|----------------|-----------------|-----------------|-----------------|-------------|-----|-------|--------------|----------------|-------------|
| variable range | to 6 | over 6 to 10 | over 10 to 18 | over 18 to 30 | over 30 to 50 | over 50 to 80 | over 80 to 120 | over 120 to 160 | over 160 to 200 | over 200 to 250 | over 250 to | all | to 5 | over 5 to 30 | over 30 to 120 | over 120 to |
| tolerance | ±0.1 | ±0.14 | ±0.19 | ±0.25 | ±0.32 | ±0.45 | ±0.57 | ±0.72 | ±0.88 | ±1.05 | ±1.25 | 0.5 | 0.025 | 0.06 | 0.12 | 0.4 |