

Jumper Wire (10 pcs)

SPECIFICATIONS:

10 pcs of 24 AWG jumper wires

Female to female

Temp. range: -25°C~80°C

Completely reusable

Rated voltage: 300 V


Included:

Jumper wire, 150 mm (10 pcs)



Art. Nr.

RND 255-00010

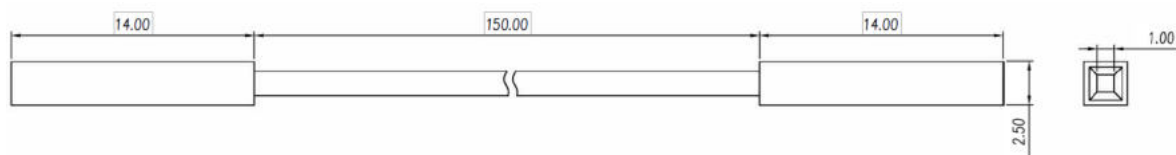

TOLERANCES EXCEPT AS NOTED

	linear dimension					fillet	chamfer	
	to 6	over 6 to 30	over 30 to 120	over 120 to 480	over 480	all	to 6	over 6 to
variable range								
tolerance	±0.5	±0.8	±1	±1.5	±2.5	±0.2	±0.5	±1