


### TOLERANCES EXCEPT AS NOTED

variable range	linear dimension				fillet	chamfer	∠short angle sid			≡	—	□	//	⊥			
	to 6	over 6 to 30	over 30 to 120	over 120 to 480	all	to 6	to 10	to 30	to 120	all	to 5	to 30	to 120	to 120			
tolerance	±0.1	±0.2	±0.3	±0.5	±0.9	±0.2	±0.5	±1	1°	30'	20'	10'	0.5	0.025	0.06	0.12	0.4

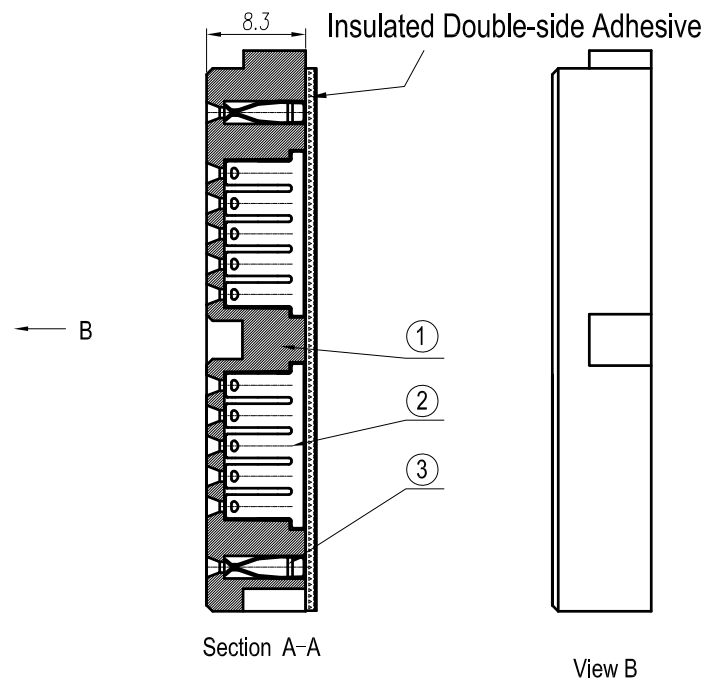

### SPECIFICATIONS:

Pitch	2.54 mm
1 Terminal strip	270 tie-point
Rated voltage/current	300 V / 3-5 A
Insulation resistance	500 MΩ / DC 500 V
Withstand voltage	AC 1000 V / 1 min
Wire range	28-20 AWG
Temp. range	-25°C ~ 80°C
Strip length	7-8 mm

Art. Nr.

RND 255-00017