


Breadboard & Jumper Wire Kit

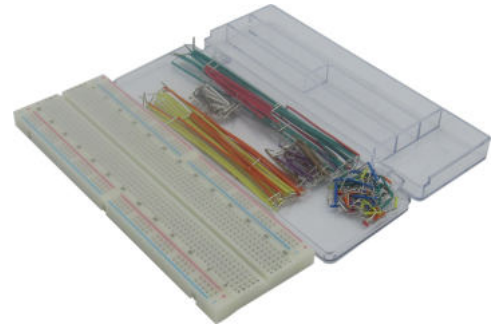


SPECIFICATIONS:

Pitch	2.54 mm
1 Terminal strip	630 tie-point
2 Distribution strips	200 tie-point
Rated voltage/current	300 V / 3-5 A
Insulation resistance	500 MΩ / DC 500 V
Withstand voltage	AC 1000 V / 1 min
Wire range	28-20 AWG
Spring clips	Brass, Ni plated
Printing	A,B,C...I,J 0,5,10,15,20...55,60
Housing material	ABS plastic



Jumper Wires

- 140 pcs of 22 AWG solid jumper wires
- Pre-cut, pre-stripped and pre-formed on each end
- 14 lengths x 10 pcs each (2/5/7/10/12/15/17/20/22/25/50/75/100/125 mm)

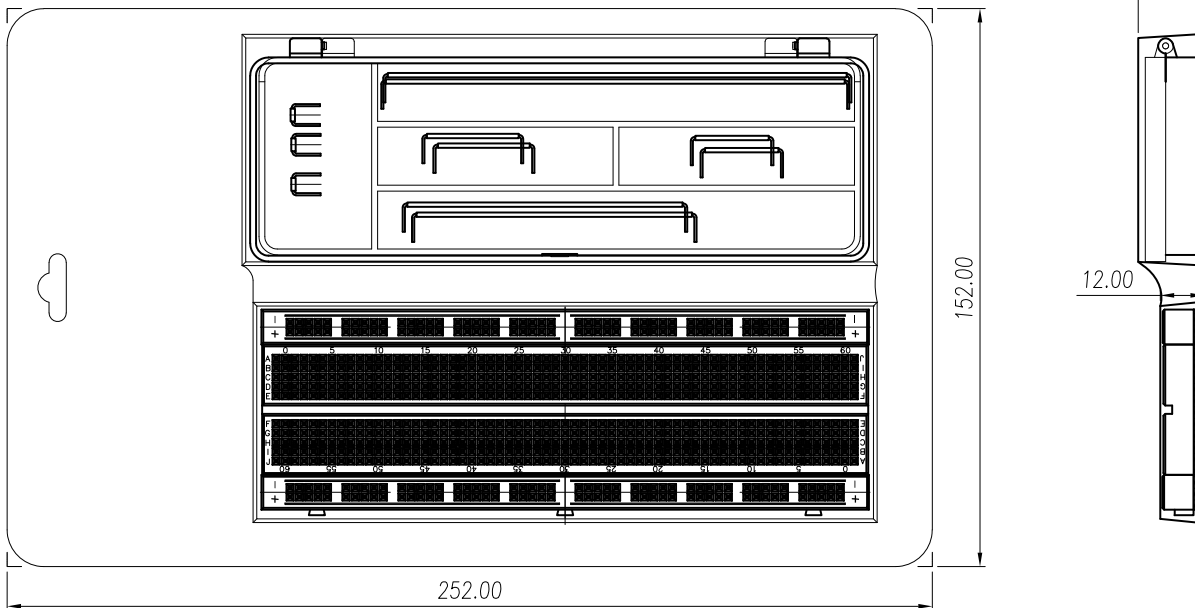

variable range	linear dimension (Tolerances Standard GB/T 14486-2008)											≡	—	□	//	⊥
	to 6	over 6 to 10	over 10 to 18	over 18 to 30	over 30 to 50	over 50 to 80	over 80 to 120	over 120 to 160	over 160 to 200	over 200 to 250	over 250 to					
tolerance	±0.1	±0.14	±0.19	±0.25	±0.32	±0.43	±0.57	±0.72	±0.88	±1.05	±1.25	0.5	0.025	0.06	0.12	0.4

Art. Nr.

RND 255-00021