


Breadboard

SPECIFICATIONS:

Pitch	2.54 mm
1 Distribution strip	640 tie-point
Rated voltage/current	300 V / 3-5 A
Insulation resistance	500 MΩ / DC 500 V
Withstand voltage	AC 1000 V / 1 min
Wire range	28-20 AWG
Temp. range	-25°C ~ 80°C
Strip length	7-8 mm
Spring clips	Bronze, Ni plated
Housing material	ABS plastic

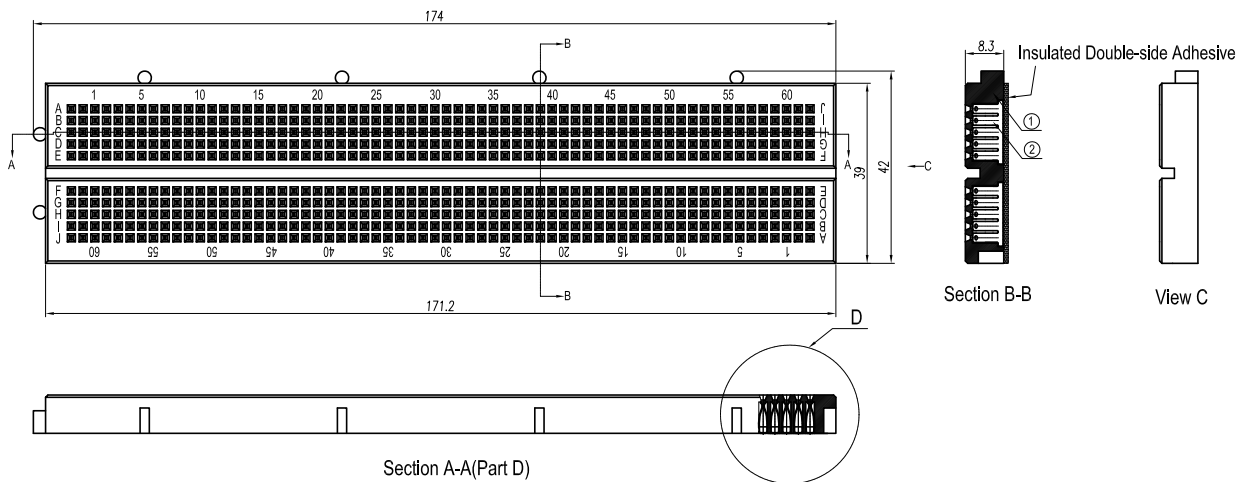

TOLERANCES EXCEPT AS NOTED

variable range	linear dimension					fillet	chamfer		∠short angle sid				≡	—	□	//	⊥
	to	over	over	over	over	all	to	over	to	over	over	over	all	to	over	over	over
tolerance	±0.1	±0.2	±0.3	±0.5	±0.9	±0.2	±0.5	±1	1'	30'	20'	10'	0.5	0.025	0.06	0.12	0.4

Art. Nr.

RND 255-00025