

# 5 Watt USB Plug Top




## Features :

- Euro Plug Top
- DOE Level VI Efficiency
- Overcurrent Protection
- Short Circuit Protection
- RoHS Compliant
- 1 Year Warranty
- EN62368 Approved

Article #	RND 320-00151	
<b>Output</b>	DC Voltage	5vdc
	Rated Current	1amp
	Current Range	0-1amp
	Rated Power	5 Watt
	Ripple & Noise	200mVp-p max
	Output Regulation	±5%
	Output Connector	USB A Socket
<b>Input</b>	Voltage Range	90-264vac
	Frequency Range	47-63Hz
	Input Current	0.3amp Max
	Energy Consumption	<0.1W Max
	Inrush Current	40mA Max
	Input Connector	Euro
	Operating Temp	0°C~40°C
<b>Environment</b>	Cooling	Convection
	Temperature Coefficient	0.05%/°C
	Humidity	5~95%RH(non-condensing)
<b>Safety &amp; EMC</b>	Storage Temp	-20°C~+80°C
	Safety Standards	CE EN62368-1
	EMC Emissions	CE EN55032, EN61000-3-2

## Mechanical Specification

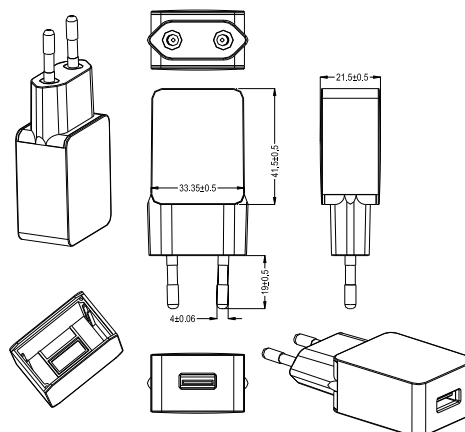

Art. Nr. 303-67-906

RND 320-00151