

# 10 Watt USB Plug Top




## Features :

- Euro Plug Top
- DOE Level VI Efficiency
- Overcurrent Protection
- Short Circuit Protection
- RoHs Compliant
- 1 Year Warranty
- EN62368 Approved

Part #	RND 500-00153	
<b>Output</b>	DC Voltage	5vdc
	Rated Current	2.1amp
	Current Range	0-2.1amp
	Rated Power	10.5 Watt
	Ripple & Noise	200mVp-p max
	Output Regulation	±5%
	Output Connector	USB Socket
<b>Input</b>	Voltage Range	90-264vac
	Frequency Range	47-63Hz
	Input Current	0.5amp Max
	Energy Consumption	<0.1W
	Average Efficiency	78.7%
	Inrush Current	40A Max
	Input Connector	Euro
<b>Environment</b>	Operating Temp	0°C~40°C
	Cooling	Convection
	Humidity	5~95%RH(non-condensing)
	Storage Temp	-20°C~+80°C
<b>Safety &amp; EMC</b>	Safety Standards	UKCA/ CE EN62368-1
	EMC Emissions	CE EN55032

## Mechanical Specification

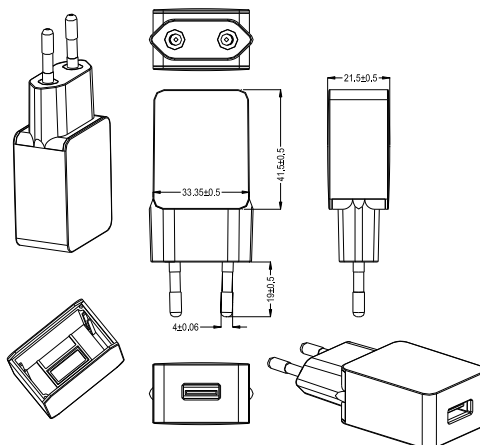

Art. Nr. 303-67-908

RND 320-00153