

# 20 Watt USB A & C socket PD Power Euro

## Plug Top



### Features:

- USB A & Type C Socket
- PD Power USB protocol - auto detect
- Euro Plug Top
- Energy Efficiency Level VI
- Protections: Short circuit & Over current
- Universal Input 90 – 264VAC
- Approvals: CE & UKCA



### Part #

**RND 320-00157**

### Output Specifications

Output Voltage	5V/9V/12V
Output Regulation	±5%
Output Current	3A/2.22A/1.67A
Rated Power	20W
Ripple & Noise	200mVp-p Max
Output Connector	USB A & USB C Socket

### Input Specifications

Input Voltage	90-264VAC
Frequency Range	50-60Hz
Standby Power	0.1W Max
Leakage Current	0.25A Max
Input Current	0.8A Max
Inrush Current	30A Max
Input Connector	Euro 2 Pin

### Environment

Operating Temp	-0°C-40°C
Cooling	Convection
Temperature Coefficient	-0.05%/°C
Humidity	5~95%RH (non-condensing)
Storage Temp	-20°C+60°C

**Art. Nr. 303-68-502**

**RND 320-00157**

# 20 Watt USB A & C socket PD Power Euro Plug Top



## Safety & EMC

Safety standards

UL/CUL 62368-1, GS/TUV EN62368-1

EMC Emissions

EN55032, FCC Part 15 Class B

## Other Specifications

Size Dimensions

61x 41 x 28.8 mm


Carton Quantity

100

Weight

0.020Kg

## Mechanical Specifications

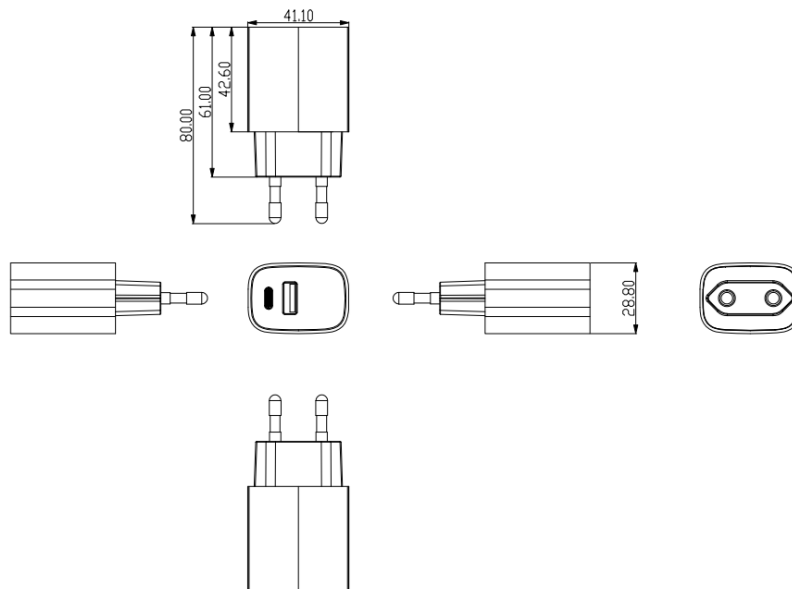

Art. Nr. 303-68-502

RND 320-00157