

# Alligator Clip w/ 4 mm Banana (female) Jack (socket)




## Applications

- To grasp conductive parts
- Very low voltage general purpose electric testing, controlling, measuring



## Specification

Electrical protection	30 V AC/ 60V DC, 16 A
Operating Temperature	-20 ... 80 °C
Conductor Material	Steel
Conformity	European Directive "RoHS" 2011/65/EU. European REACH regulation n°1907 / 2006.
Environment	"RoHS" compliant, Pb ≤ 4 % in conductor, Pb ≤ 0.1 % in insulator, Hg ≤ 0.1 %, Cr VI ≤ 0.1 %, Cd ≤ 0.01 %, PBB ≤ 0.1 %, and PBDE ≤ 0.1 %. "REACH" compliant, no substances from the candidate list of SVHC for authorisation at mass concentrations greater than 0.1 %.

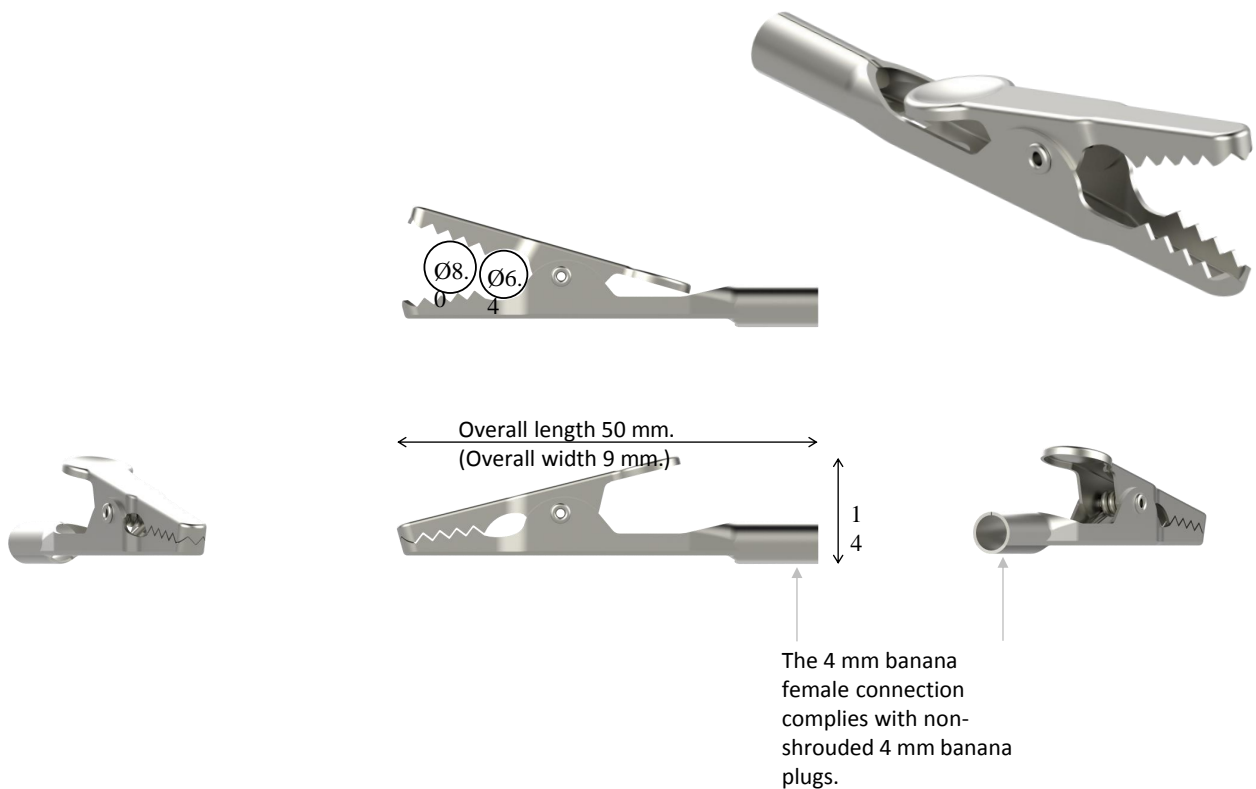

**RND Part Nr.**  
RND 350-00026