

4 mm Banana (female) Jack to 2 mm Banana (male) Plug Adapter



Applications

- To convert a 2 mm banana female socket into a shrouded 4 mm banana female socket
- General purpose electric and electronic testing, controlling, measuring




RND 350-00051



RND 350-00050

Specification

Electrical protection	30 VAC / 60 VDC, 10 A @ 40 °C
Operating Temperature Max.	80 °C
Operating Temperature Min.	-20 °C
Conductor Material	Nickel Coated Brass
Environment	<p>"RoHS" compliant, Pb ≤ 4 %, Hg ≤ 0.1 %, Cr VI ≤ 0.1 %, Cd ≤ 0.01 %, PBB ≤ 0.1 %, PBDE ≤ 0.1 %, DEHP ≤ 0.1 %, BBP ≤ 0.1 %, DBP ≤ 0.1 %, and DIBP ≤ 0.1 %.</p> <p>"REACH" compliant, no substances from the candidate list of SVHC for authorization at mass concentrations greater than 0.1 %.</p>

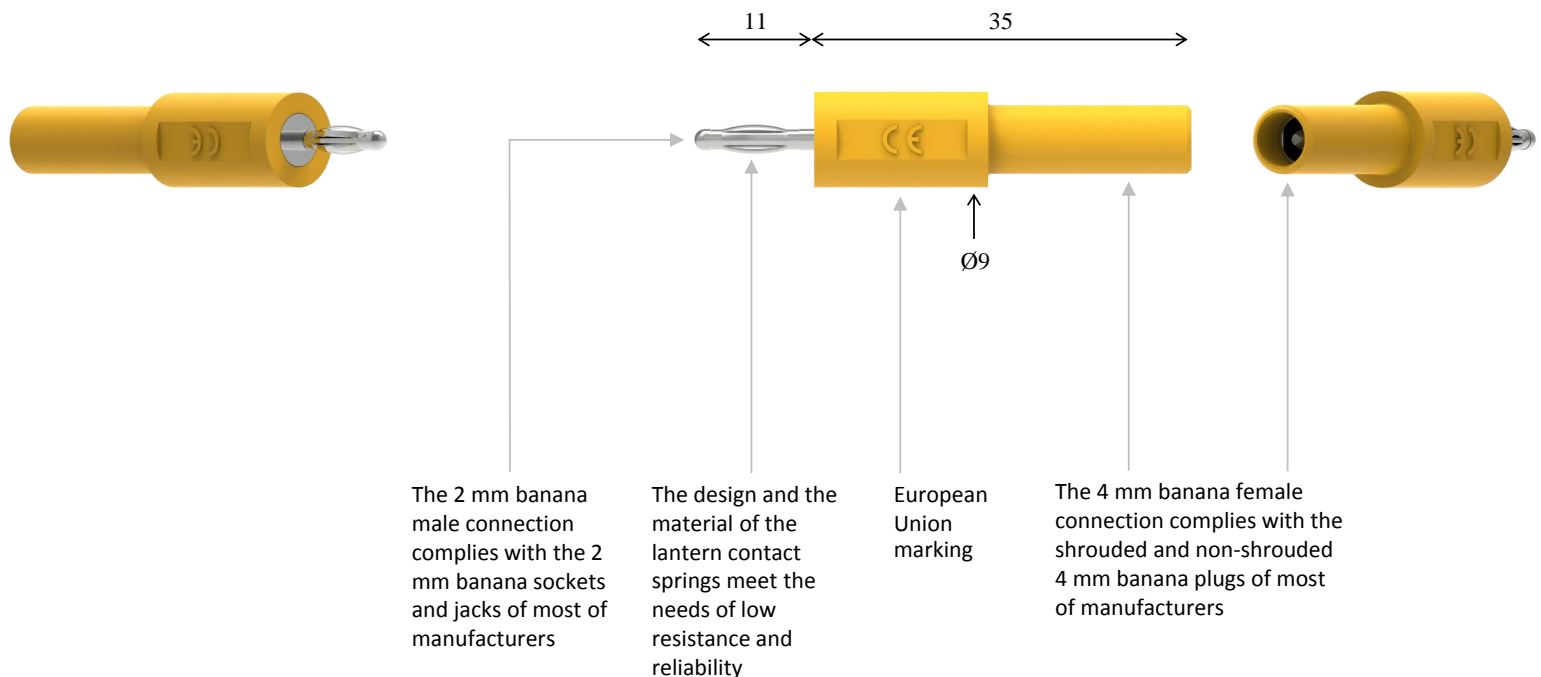

RND Part Nr.	Colour
RND 350-00050	Red
RND 350-00051	Black