

# Alligator Clip Test Lead Kit

## 8 PCS



### Applications

- To short and stunt
- Very low voltage general purpose and electronic testing, controlling, measuring

### Set Includes

2x Black

1x Blue

1x Green

2x Red

1x White


1x Yellow

Test leads, each with two alligator clips



### Specification

Electrical protection	30 VAC / 60 VDC, 6 A @ 40 °C
Operating Temperature Max.	60 °C
Operating Temperature Min.	-20 °C
Conductor Material	Red annealed Copper and Nickel Coated Steel
Jacket Material	PVC
Environment	RoHS compliant, Pb ≤ 4 %, Hg ≤ 0.1 %, Cr VI ≤ 0.1 %, Cd ≤ 0.01 %, PBB ≤ 0.1 %, PBDE ≤ 0.1 %, DEHP ≤ 0.1 %, BBP ≤ 0.1 %, DBP ≤ 0.1 %, and DIBP ≤ 0.1 %. REACH compliant, no substances from the candidate list of SVHC for authorization at mass concentrations greater than 0.1 %.

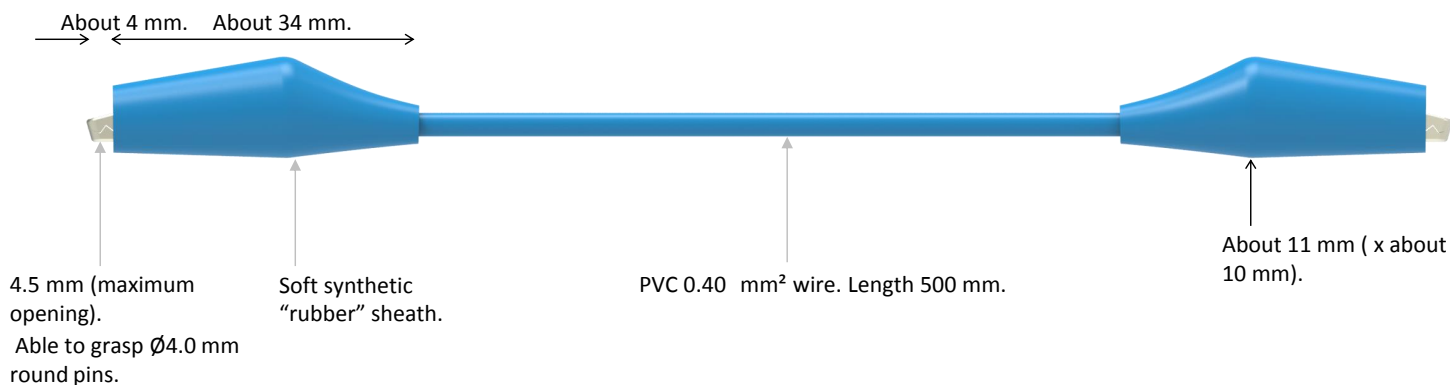

**RND Part Nr.**  
RND 350-00074