



Rigid Test Clip with Alligator Clips & 4mm Connection

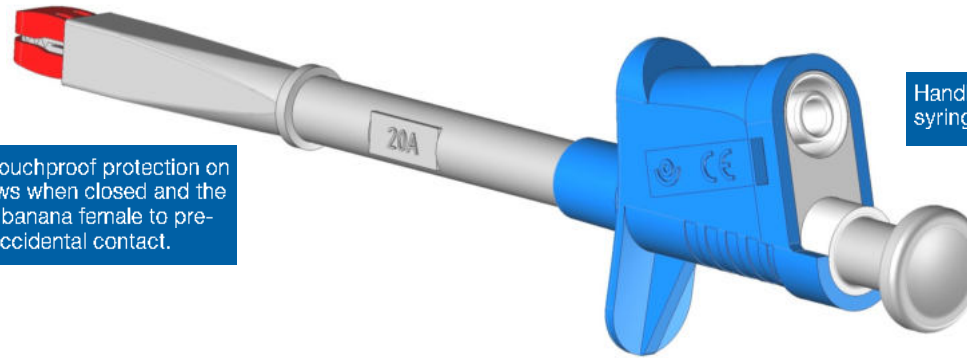

IP2X touchproof protection on the jaws when closed and the 4 mm banana female to prevent accidental contact.

Handling is eased by the syringe-type ergonomics.

Optimum jaw design to clench well a lot of various items as bar, wire, screw, PCB pin, etc.

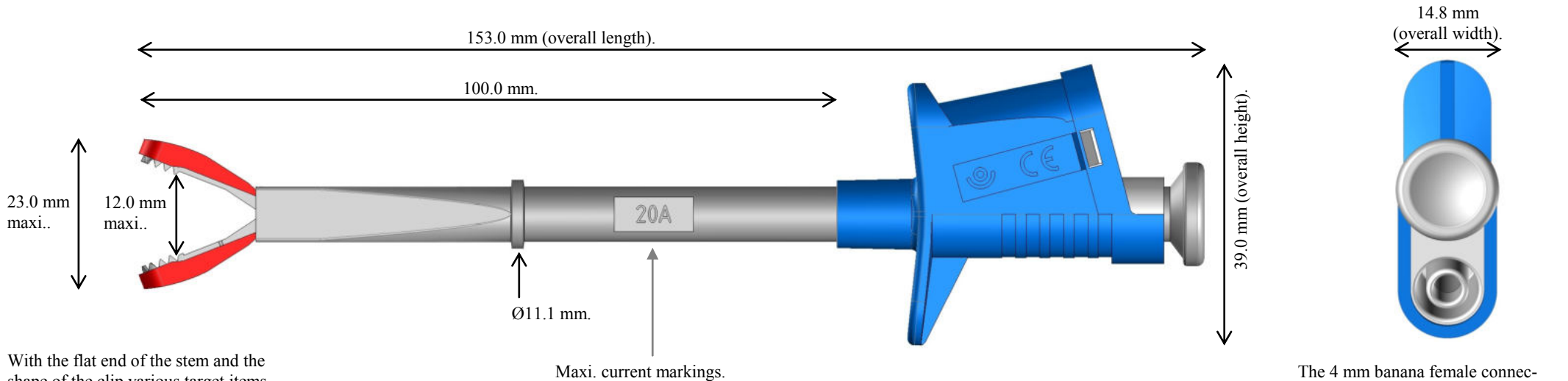

With the flat end of the stem and the shape of the clip various target items can be clenched and the electrical contact is reliable.

The 4 mm banana female connection complies with the 4 mm banana plugs of most of the worldwide most famous manufacturers.

Rigid Test Clip with Alligator Clips & 4mm Connection



Specification

Electrical protection	1000 V CAT II , 1000 V CAT III , 600 V CAT IV , reinforced insulation, pollution degree 2 , 6 A
Operating Temperature Range	-20 °C...+80 °C

RND Part Nr.	Colour
RND 350-00117	Black
RND 350-00118	Red