

Type K Standard Quick Wire Thermocouple Connector



Features


- Easy 'jab-in' connection for rapid termination
- Just push wire in and tighten screw
- Contacts are polarised to prevent incorrect connection



Specification

Thermocouple	K
Connector Type	Quick Wire Socket
Connector Size	Standard
Colour	Green
Max. Temperature	220 °C
+Positive Contact	Nickel Chromium
-Negative Contact	Nickel Alloy
Standards Met	BS EN 50212:1997. RoHS

Drawing

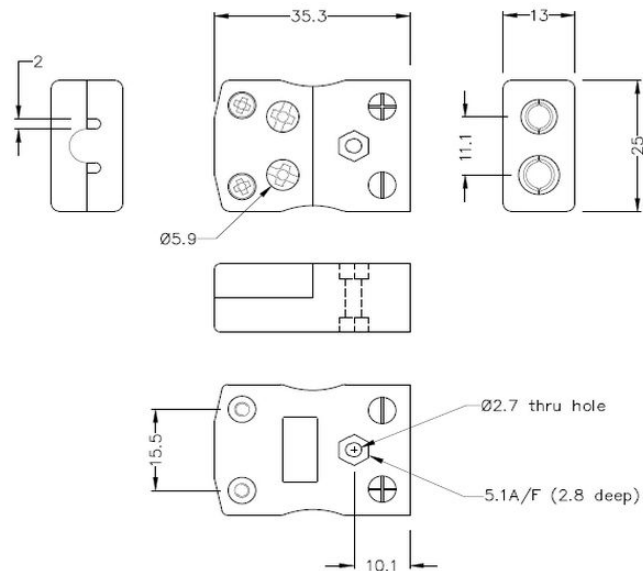

Standard in-line Socket - Quick Wire
(dimensions in mm)

Art. Nr.
RND 410-00084