

Type K Standard Thermocouple Connector Cable Mount Socket



Features


- Accepts standard round plug pins
- Suitable for industrial applications
- Contacts are polarised to prevent incorrect connection



Specification

Thermocouple	K
Connector Type	Socket
Connector Size	Standard
Colour	Green
Max. Temperature	220 °C
+Positive Contact	Nickel Chromium
-Negative Contact	Nickel Alloy
Standards Met	BS EN 50212:1997. RoHS

Drawing

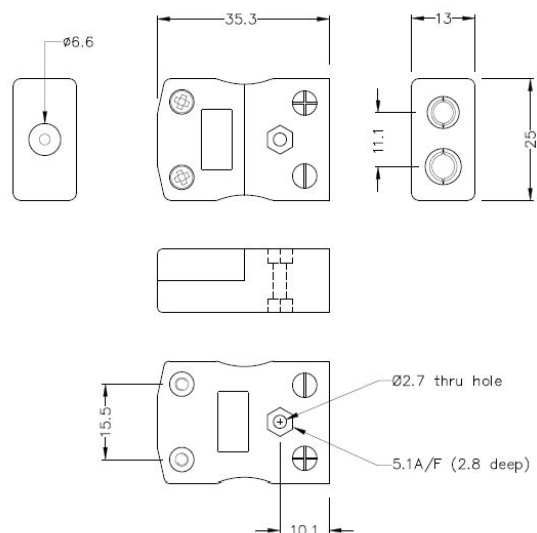

Standard in-line Socket
(dimensions in mm)

Art. Nr.
RND 410-00086