


Insulated Exposed Junction Thermocouple with Mini Plug Type K 2m

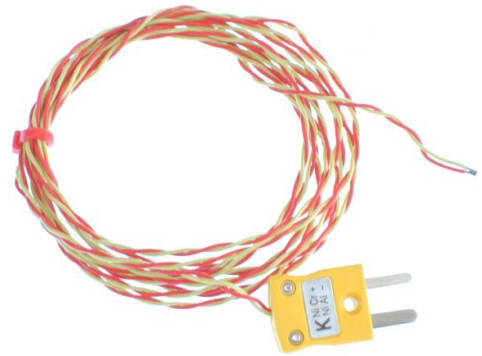

Features

- Fast response
- Welded exposed junction
- Durable construction with PFA Insulation for resistance to oils, acid, fluids and good mechanical strength and flexibility
- Mini plug termination for quick and easy connection



Specification

| | |
|-------------------------|-----------------------|
| Thermocouple Type | K |
| Thermocouple Junction | Exposed |
| Cable Length | 2 m |
| Cable Type | Twin-Twisted Lead |
| Insulation | PFA |
| Conductors | 1 |
| Conductor Cross Section | 0.315 mm ² |
| Cable Termination | Mini Plug |
| Max. Temperature | +250 °C |
| Min. Temperature | -75 °C |
| Standards Met | ANSI MC96.1 |

Art. Nr.
RND 410-00097