


Glassfibre Insulated Exposed Junction Thermocouple Type K 5m

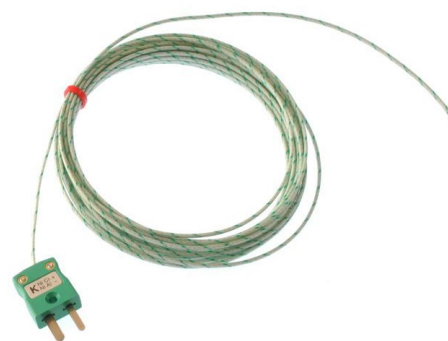

Features

- Fast response
- Ideal for Test & Development applications
- Welded exposed junction available with a miniature plug termination or open ends
- Good temperature resistance (not suitable in fluids)



Specification

Sensor Type	Exposed Junction
Thermocouple Type	K
Cable Length	5 m
Insulation	Glassfibre
Conductors	1
Conductor Cross Section	0.315 mm ²
Termination Type	Miniature Flat Pin Plug Colour Coded in Accordance IEC 584
Max. Temperature	+350 °C (short periods up to 400 °C)
Min. Temperature	-60 °C
Tolerance	Class 2
Standards Met	IEC-584-3
Connector Type	Plug
Connector Size	Miniature

Art. Nr.
RND 410-00099