


Insulated Exposed Junction Open End Type K 5m

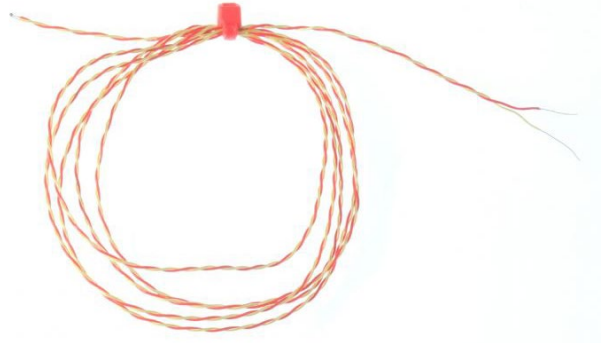

Features

- Fast response
- Welded exposed junction



Specification

Thermocouple Type	K
Thermocouple Junction	Exposed
Cable Length	5 m
Cable Type	Twin-Twisted Lead
Insulation	PFA
Conductors	1
Conductor Cross Section	0.315 mm ²
Cable Termination	Open End
Max. Temperature	+250 °C
Min. Temperature	-75 °C
Standards Met	ANSI MC96.1

Art. Nr.
RND 410-00109