


# Grounded Thermocouple Type J Stainless Steel Overbraided Cable 2m

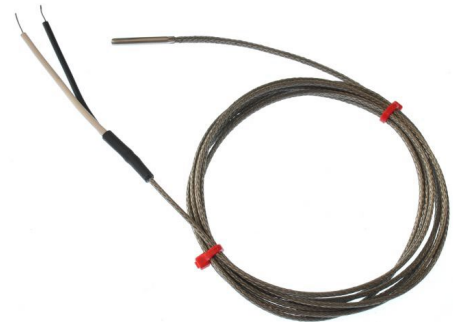

## Features

- Thermocouple junction is grounded at tip for fast response
- Various probe diameters are available in this range
- Fast response time provided by the grounded tip at the junction



## Specification

Sensor Type	316 Stainless Steel tube 4 x 40 mm
Thermocouple Type	J
Thermocouple Junction	Grounded at tip for fast response
Cable Length	2 m
Cable Type	Glassfibre Stainless Steel Overbraided Cable
Cable Termination	Open End
Max. Temperature	+350 °C
Min. Temperature	-60 °C

**Art. Nr.**  
**RND 410-00117**