

## Features



- One-Touch tube fittings are used in pneumatics piping
- The tube fittings come in a wide variety of models to meet all your needs in pneumatics piping
- Even after installation, the direction of the tube can be changed freely
- Ensures Anti-Corrosion and Anti-Contamination



## Specification

Medium	Air, Vacuum
Operating Pressure	0-1.0 Mpa
Max Pressure	1.5 Mpa
Operating Temperature	5-60 °C
Body Material	Polybutylene Terephthalate (PBT)

## Product Range & Drawing

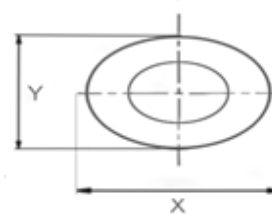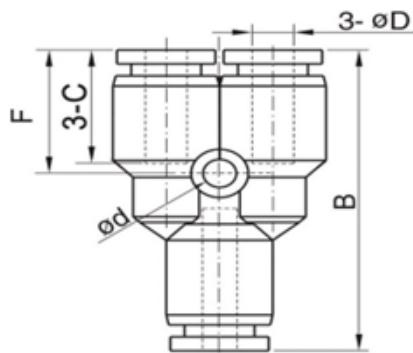

Part Number	øD (mm)	ød (mm)	B (mm)	C (mm)	F (mm)	X (mm)	Y (mm)
RND 425-00103	6	3.5	34.4	14.8	14.6	13.8	12.5
RND 425-00104	8	3.5	39.8	17.6	17.4	15.8	13.9
RND 425-00105	10	4.5	42	18.3	18	19.4	17
RND 425-00106	12	4.5	53	23	21.5	21.7	20