

Pneumatic Fittings



Features


- One-Touch tube fittings are used in pneumatics piping
- The tube fittings come in a wide variety of models to meet all your needs in pneumatics piping
- Even after installation, the direction of the tube can be changed freely
- Ensures Anti-Corrosion and Anti-Contamination



Specification

Medium	Air, Vacuum
Operating Pressure	0-1.0 Mpa
Max Pressure	1.5 Mpa
Operating Temperature	5-60 °C
Body Material	Brass

Product Range & Drawing

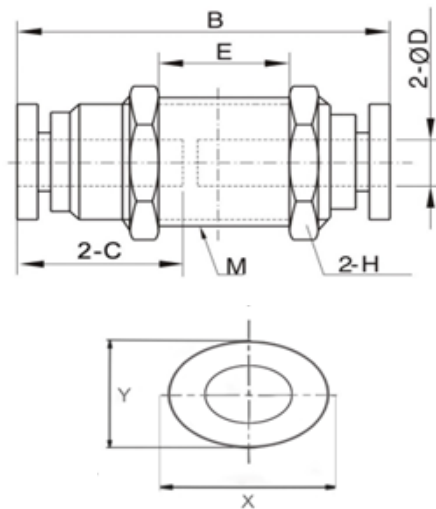

Part Number	øD (mm)	M (mm)	E (mm)	B (mm)	H (mm)	X (mm)	Y (mm)	C (mm)
RND 425-00107	6	M14	9.5	32	17	13.8	12.5	15
RND 425-00108	8	M16	11.1	35	19	15.8	13.9	17
RND 425-00109	10	M20	12.7	39	24	19.4	17	19
RND 425-00110	12	M22	14.5	45	27	21.7	20	21.5