

Features




- One-Touch tube fittings are used in pneumatics piping
- The tube fittings come in a wide variety of models to meet all your needs in pneumatics piping
- Even after installation, the direction of the tube can be changed freely
- Nickel-Plated brass body ensures Anti-Corrosion and Anti-Contamination
- All R and NPT threads are Pre-Coated sealant
- All cylindrical threads are standard with O-Ring seals



Specification

Medium	Air, Vacuum
Operating Pressure	0-1.0 Mpa
Max Pressure	1.5 Mpa
Operating Temperature	5-60 °C
Body Material	Brass

Product Range & Drawing

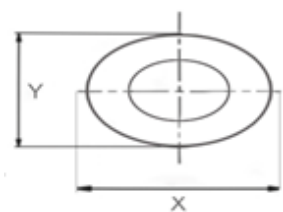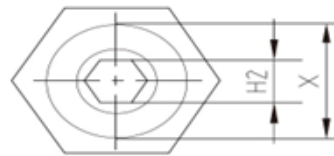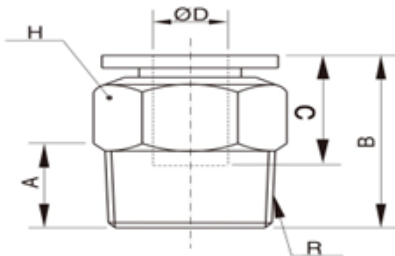

Part Number	øD (mm)	R	A (mm)	B (mm)	H (mm)	H2 (mm)	X (mm)	Y (mm)	C (mm)
RND 425-00115	6	R 1/8	7	21	12	4	13.8	12.5	15
RND 425-00116	6	R 1/4	9	21	14	4	13.8	12.5	15
RND 425-00117	6	R 3/8	10	21	17	4	13.8	12.5	15
RND 425-00118	6	R 1/2	13	23.5	21	4	13.8	12.5	15
RND 425-00119	8	R 1/8	7	23.8	14	5	15.8	13.9	17
RND 425-00120	8	R 1/4	9	23.8	14	6	15.8	13.9	17
RND 425-00121	8	R 3/8	10	20.8	17	6	15.8	13.9	17
RND 425-00122	8	R 1/2	13	24.2	21	6	15.8	13.9	17
RND 425-00123	10	R 1/4	9	28.7	17	6	19.4	17	19
RND 425-00124	10	R 3/8	10	26	17	8	19.4	17	19
RND 425-00125	10	R 1/2	13	25.3	21	8	19.4	17	19
RND 425-00126	12	R 1/4	9	32.2	21	6	21.7	20	21.5
RND 425-00127	12	R 3/8	10	29	21	8	21.7	20	21.5
RND 425-00128	12	R 1/2	13	31.2	21	8	21.7	20	21.5