

Features


- This design allows for changes in direction in a piping system, facilitating the redirection of fluid flow at right angles
- The L-shaped configuration of these fittings is often space-efficient, making them suitable for tight or confined spaces where a smooth change in direction is needed
- They also offer different connection options, such as threaded, socket weld, or compression fittings, providing flexibility in system design and assembly



Specification

Material	Brass
Medium	Air , Steam , Water
Thread	BSPP
Tolerance	+/-0.01-0.05 mm
Working Temperature	-100 ~ 500 ° C
Maximum Pressure	3600 psi/ 25 MPa

Product Range & Drawing

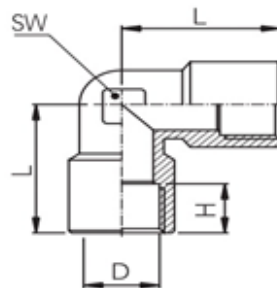

Part Number	D	L (mm)	H (mm)	SW (mm)
RND 425-00276	G 1/8	18	7	10
RND 425-00277	G 1/4	25	11	11.5
RND 425-00278	G 3/8	27.5	11.5	12.7
RND 425-00279	G 1/2	32.5	14	16