

Features


- T-Fittings are known for their excellent resistance to corrosion
- T-Fittings can withstand mechanical stress and pressure, making them reliable for use in plumbing, industrial equipment, or other situations where strength is crucial
- They are available in various configurations, sizes, and thread types, allowing for compatibility with a wide range of systems and facilitating ease of installation in diverse settings



Specification

Medium	Air , Steam , Water
Thread Standard	BSPP 1/8 = G Thread
Technics	Forged and CNC machining
Tolerance	+/-0.01-0.05 mm
Finishing	Zinc/nickel/chrome plated, polish, anodize, passivated, oxidation etc
Working Temperature	-100 ~ 500 ° C
Maximum Pressure	3600 psi/ 25 MPa

Product Range & Drawing

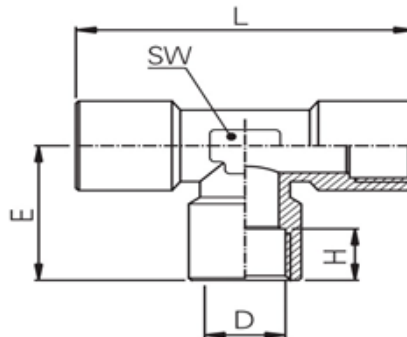

Part Number	D	L (mm)	E (mm)	H (mm)
RND 425-00280	G 1/8	41	20.5	9
RND 425-00281	G 1/4	50	25	11
RND 425-00282	G 3/8	54	27	13
RND 425-00283	G 1/2	64	32	15