

Features


- Pneumatic fittings feature a quick-connect/disconnect mechanism, facilitating rapid assembly and disassembly of pneumatic systems
- X-Fittings can withstand mechanical stress and pressure, making them reliable for use in plumbing, industrial equipment, or other situations where strength is crucial
- They are available in various configurations, sizes, and thread types, allowing for compatibility with a wide range of systems and facilitating ease of installation in diverse settings



Specification

Material	Brass
Medium	Air , Steam , Water
Thread	BSPB
Tolerance	+/-0.01-0.05 mm
Working Temperature	-100 ~ 500 ° C
Maximum Pressure	3600 psi/ 25 MPa

Product Range & Drawing

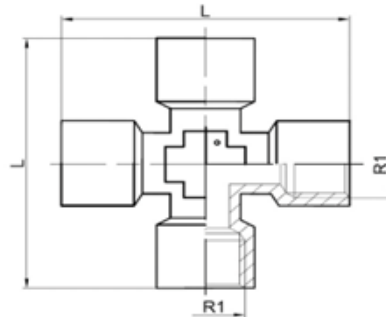

Part Number	R1	L (mm)
RND 425-00296	G 1/8	42
RND 425-00297	G 1/4	50
RND 425-00298	G 3/8	55.5
RND 425-00299	G 1/2	64.5