

## Features

- For external oscillator
- Loud volume
- Compact dimensions




## Basic Condition

Voltage Rating	12 Vp-p Square Wave
Operating Voltage	1 ... 30 Vp-p
Operating Temperature	-20 ... 70 °C
Storage Temperature Range	-30 ... 80 °C


## Electrical Characteristics

Sound Press Level	$\geq 90$ dB @ 100 mm / 9 Vp-p
Consumption Current	$\leq 5$ mA @ 9 Vp-p
Tone Type	Continuous
Resonate Frequency	4 kHz +/- 300 Hz
Capacitance	30 nF 30% @ 120 Hz
Material	ABS

## Measuring Method

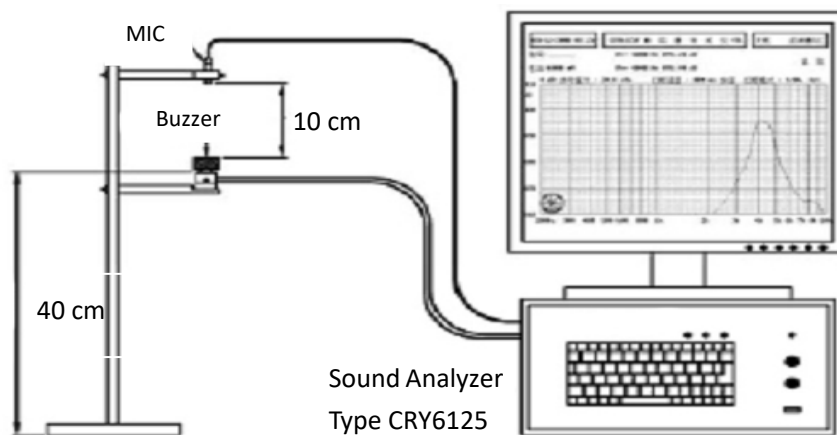


## Frequency Curve

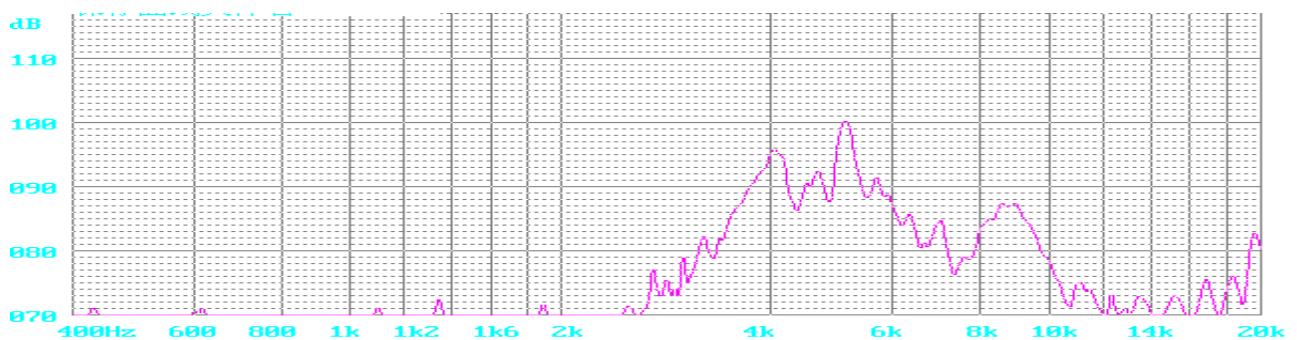

# Piezo Buzzer

## Drawing

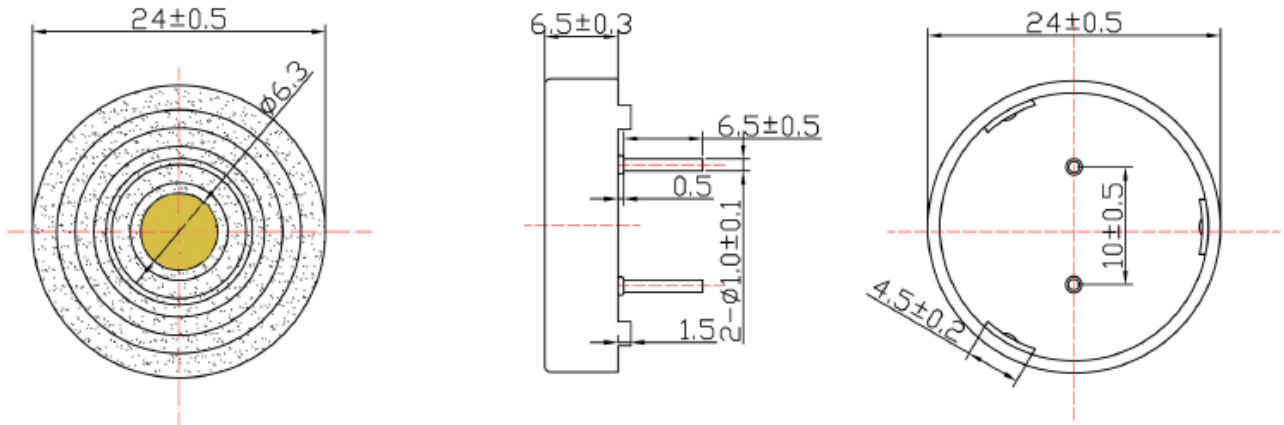

Art Nr.  
RND 430-00031