



BABY TWS Signal Tower (Red + Green)



RND 430-00067

Torretta di segnalazione luminosa

*Luminous warning STACK LIGHT.
Colonne de signalisation lumineuse.
Signalsäule
Columna luminosa.*

| | | | | | |
|---|---|--|-----------|----------|-----|
| CORPO <i>BODY CORPS GEHAUSE CUERPO DEL PRODUCTO</i> | PC | | | | |
| GRUPPO OTTICO <i>LUMINOUS SOURCE SOURCE LUMINEUSE LICHTQUELLE FUENTE DE LUZ</i> | N°14 LED | | | | |
| COLORI DISPONIBILI <i>AVAILABLE COLOURS COULEURS DISPONIBLES VERFÜGBARE FARBEN COLORES DISPONIBLE</i> |   | | | | |
| TENSIONE DI ALIMENTAZIONE <i>VOLTAGE TENSION SPANNUNG TENSIÓN</i> | 24 Vac/dc | | | | |
| SERVIZIO <i>OPERATION FONCTIONNEMENT BETRIEBSART FUNCIONAMIENTO</i> | ∞ | | | | |
| CORRENTE NOMINALE <i>CURRENT CONSUMPTION CONSUMMATION DE COURANT STROMAUFNAHME CONSUMO DE CORRIENTE</i> | <table border="1"><tr><td></td><td>24 Vac/dc</td></tr><tr><td>MAX (mA)</td><td>100</td></tr></table> | | 24 Vac/dc | MAX (mA) | 100 |
| | 24 Vac/dc | | | | |
| MAX (mA) | 100 | | | | |
| MODALITA' LUCE <i>LIGHT EFFECT EFFET LUMINEUX LICHTEFFEKT EFECTO LUMINOSO</i> | Fissa <i>Steady Fixe Dauerlicht Luz fija</i> | | | | |
| GRADO IP <i>IP RATING DEGRE IP SCHUTZART GRADO IP</i> | IP65 | | | | |
| TEMPERATURA DI FUNZIONAMENTO <i>OPERATING TEMPERATURE TEMPERATURE DE SERVICE BETRIEBSTEMPERATUR TEMPERATURA DE FUNCIONAMIENTO</i> | -30°C+50°C | | | | |
| CERTIFICAZIONI, OMOLOGAZIONI <i>CERTIFICATIONS, APPROVALS CERTIFICACIONES, HOMOLOGATIONS PRODUKTZERTIFIKATE, ZULASSUNGEN CERTIFICADOS, HOMOLOGACIONES</i> | CE, UKCA | | | | |

BABY TWS Signal Tower (Red + Green)



FISSAGGIO


MOUNTING
FIXATION
FIXIERUNG
FIJACIÓN

Viti su base

Screws on the base
Par vis sur la base
Mit Schrauben am Sockel
Tornillos en la base

DISEGNO

TECHNICAL DRAWING
DESSIN
TECHNISCHE ZEICHNUNG
DIBUJO TECNICO

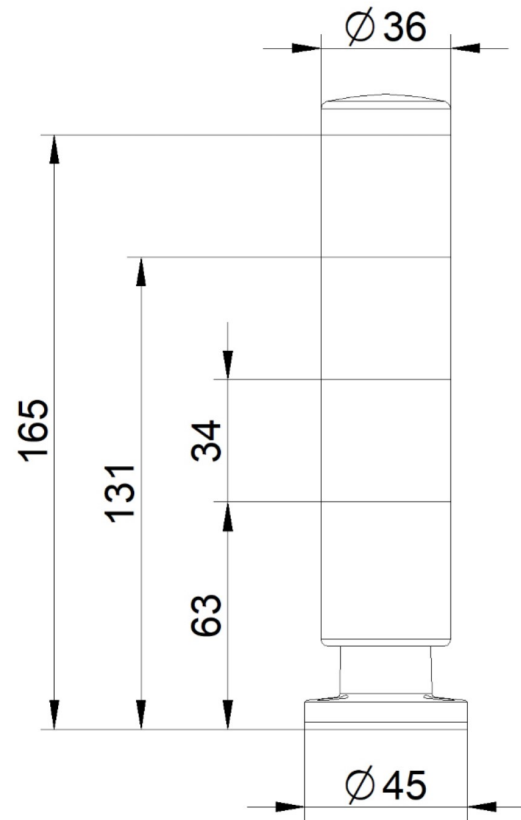

COLLEGAMENTO ELETTRICO

ELECTRICAL WIRING
RACCORDEMENT ELECTRIQUE
ELEKTRISCHE VERBINDUNG CONEXIÓN
ELÉCTRICA

