

MICRO W10 Electro-Mechanical Siren



RND 430-00122

Sirena elettromeccanica per applicazioni industriali.

Electromechanical siren for industrial applications.

Sirène électromécanique pour applications industrielles.

Elektromechanische Sirene für industrielle Anwendunge.

Sirena electromecánica para aplicaciones industriales.

CORPO BODY CORPS KORPS CUERPO	PC/ABS				
MUSETTO FRONTAL HEAD PARTIE FRONTALE FRONTALER KOPF CABEZA FRONTAL	ABS				
VENTOLA FAN VENTILATEUR LÜFTER VENTOLADOR	Acetalica Acetal resin-based Résine acétal Harz Acetal Resina acetálica				
VOLTAGGIO VOLTAGE TENSION SPANNUNG TENSIÓN	24VDC				
SERVIZIO OPERATION FONCTIONNEMENT BETRIEBSART FUNCIONAMIENTO	∞				
CORRENTE NOMINALE CURRENT CONSUMPTION CONSOMMATION DE COURANT STROMAUFNAHME CONSUMO DE CORRIENTE	<table border="1"> <tr> <td></td> <td>24Vdc</td> </tr> <tr> <td>A (Max)</td> <td>0,65</td> </tr> </table>		24Vdc	A (Max)	0,65
	24Vdc				
A (Max)	0,65				
RESA ACUSTICA ACOUSTIC OUTPUT RENDEMENT ACOUSTIQUE SCHALLLEISTUNGSPEGEL SALIDA ACUSTICA	<table border="1"> <tr> <td></td> <td>24Vacdc</td> </tr> <tr> <td>dB(A)1m</td> <td>96</td> </tr> </table>		24Vacdc	dB(A)1m	96
	24Vacdc				
dB(A)1m	96				
SUONO SOUND TONALITE' SOUND SONIDO	LINEARE Linear Linear Lineare Linear				
GRADO IP IP RATING DEGRE IP SCHUTZART GRADO IP	IP42				
TEMPERATURA DI FUNZIONAMENTO OPERATING TEMPERATURE TEMPERATURE DE SERVICE BETRIEBSTEMPERATUR TEMPERATURA DE FUNCIONAMIENTO	-30°C+40°C				

MICRO W10 Electro-Mechanical Siren



CERTIFICAZIONI, OMOLOGAZIONI

CERTIFICATIONS, APPROVALS CERTIFICAZIONI,
HOMOLOGATIONS PRODUKTZERTIFIKATE,
ZULASSUNGEN CERTIFICADOS, HOMOLOGACIONES

CE, UKCA

FISSAGGIO



MOUNTING
FIXATION
FIXIERUNG
FIJACIÓN

Viti su base

Screws on the base
Par vis sur la base
Mit Schrauben am Sockel
Tornillos en la base

DISEGNO

TECHNICAL DRAWING
DESSIN
TECHNISCHE ZEICHNUNG
DIBUJO TECNICO

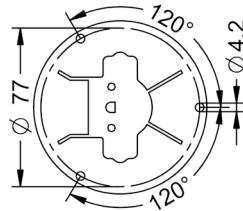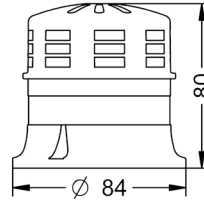

0,15 Kg