

Plastic enclosure

80 x 80.6 x 23.5 mm orange ABS IP 00




Tightly fit self-locking lids or lids with guides
 Outer clamping for mounting
 Suitable cable diameter is 3-6mm for cable outlet

SPECIFICATION:

Dimensions L x W x H	80 x 80.6 x 23.5 mm
Colour	orange
Material	ABS
Protection rating	IP 00
Fire class	UL 94 HB
Mounting	Flange
Temperature range	max. +70 °C



Art. Nr.
RND 455-00337

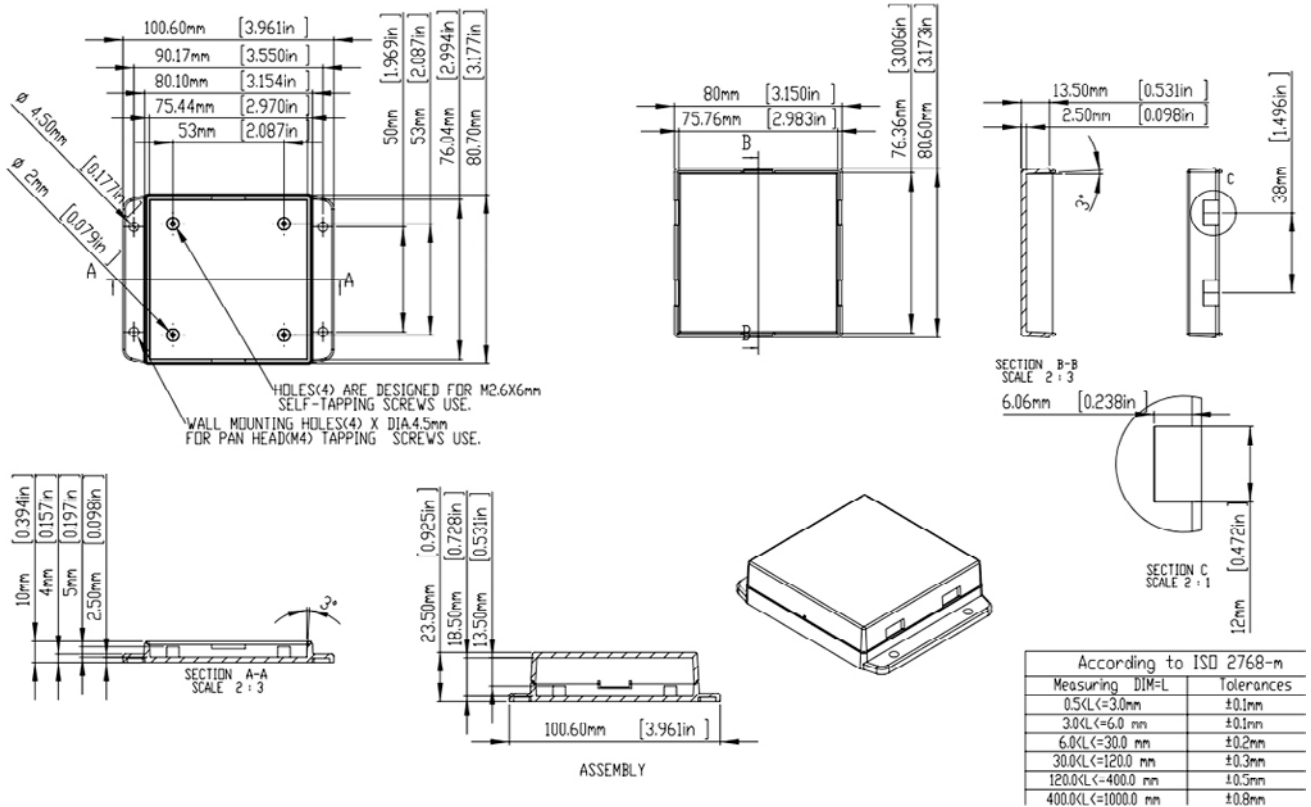

According to ISO 2768-m		
Measuring DIM=L		Tolerances
0.5<L<=3.0mm		±0.1mm
3.0<L<=6.0 mm		±0.1mm
6.0<L<=30.0 mm		±0.2mm
30.0<L<=120.0 mm		±0.3mm
120.0<L<=400.0 mm		±0.5mm
400.0<L<=1000.0 mm		±0.8mm