


Features

- Easy to install: fast and simple integration ensure stable performance in any application
- Waterproof, IP66 / IP68 protection
- Safe and reliable
- For use with outdoor lighting, sensor equipment, outdoor communication equipment & more

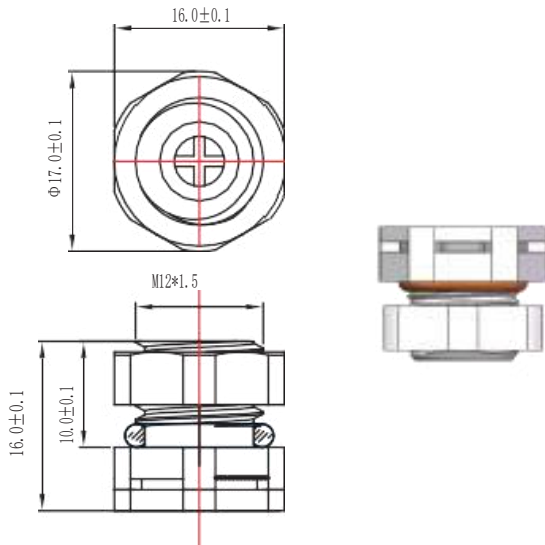

Specification

Air Permeability	350-4000 ml/min@0.07bar
Membrane Material	ePTFE
Membrane Characteristics	Oleophobic & Hydrophobic
Body Material	PA66+25% glass fiber
Colour	Iron Grey
Torque Wrench Size	16
O-ring Material	Silica gel 60H shore hardness A
Clamping Nut Material	PA66
Flammability Level	V0
Salt Resistance	$10 < 0.1\%$
Antibacterial Level (GB/T 2423.16)	1 Level
Anti High & Low Temperature	$-40^{\circ}\text{C} \sim 120^{\circ}\text{C}$
IP Level	IP66 / IP68
Traceability	With Independent Laser Serial No.
Recommended Torque	$0.7 \pm 0.1 \text{ N.m}$
Installation	Thread

Art. Nr.
RND 455-01107