

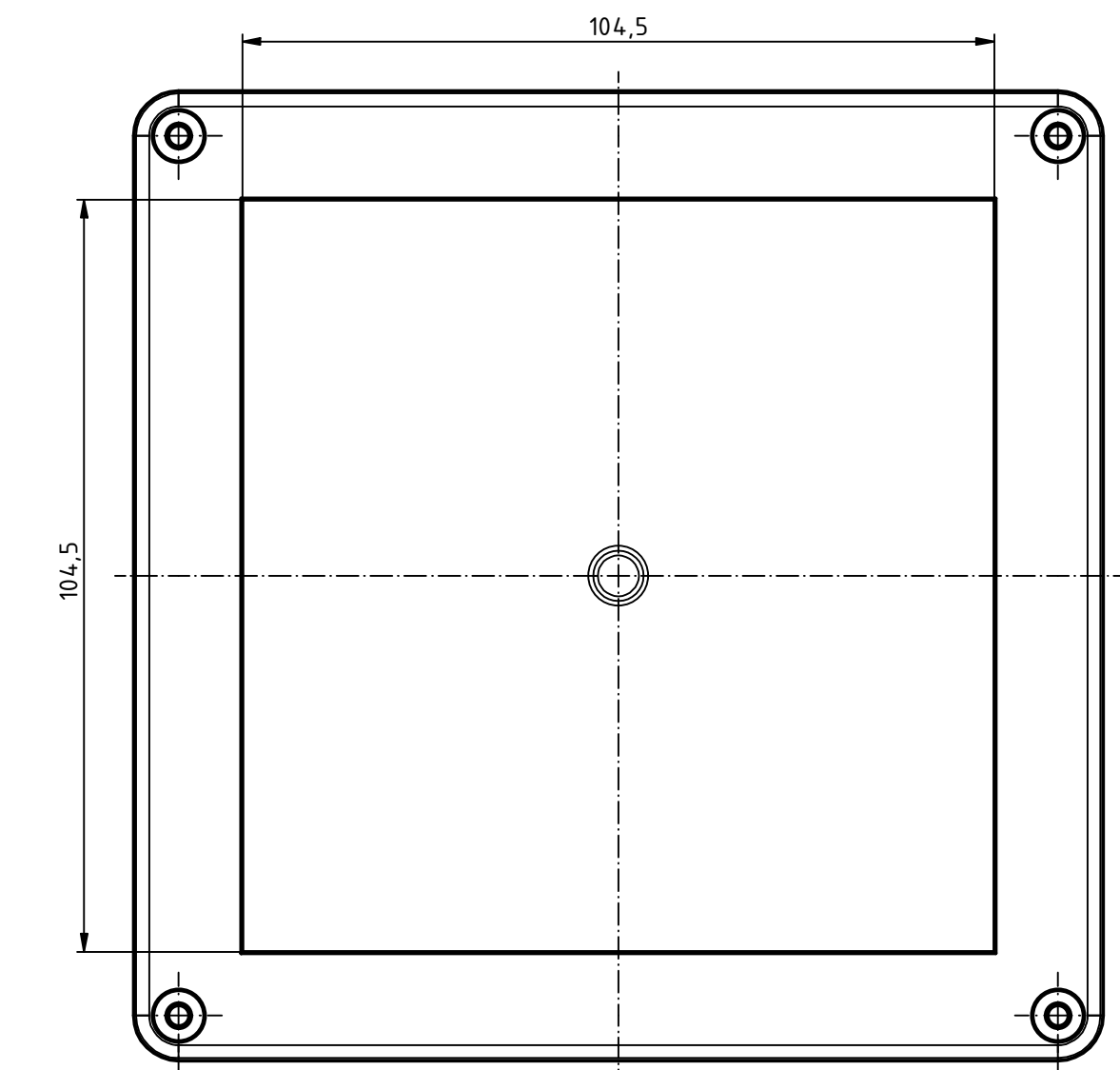
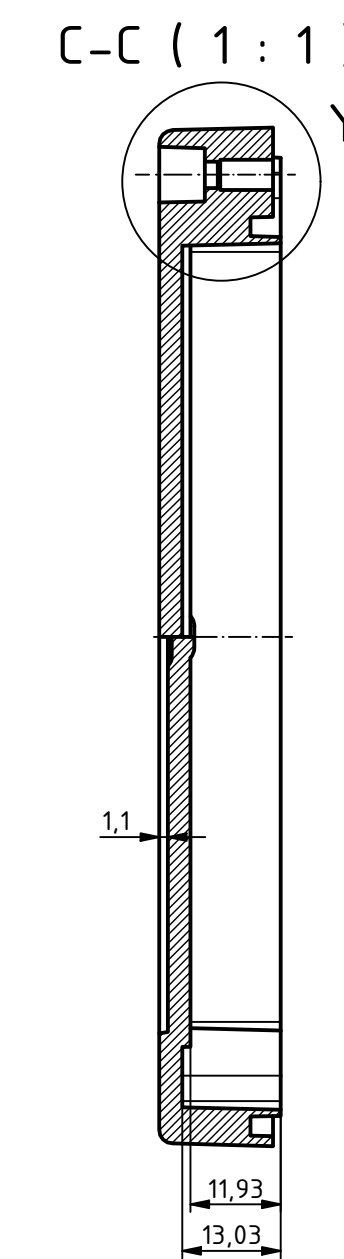
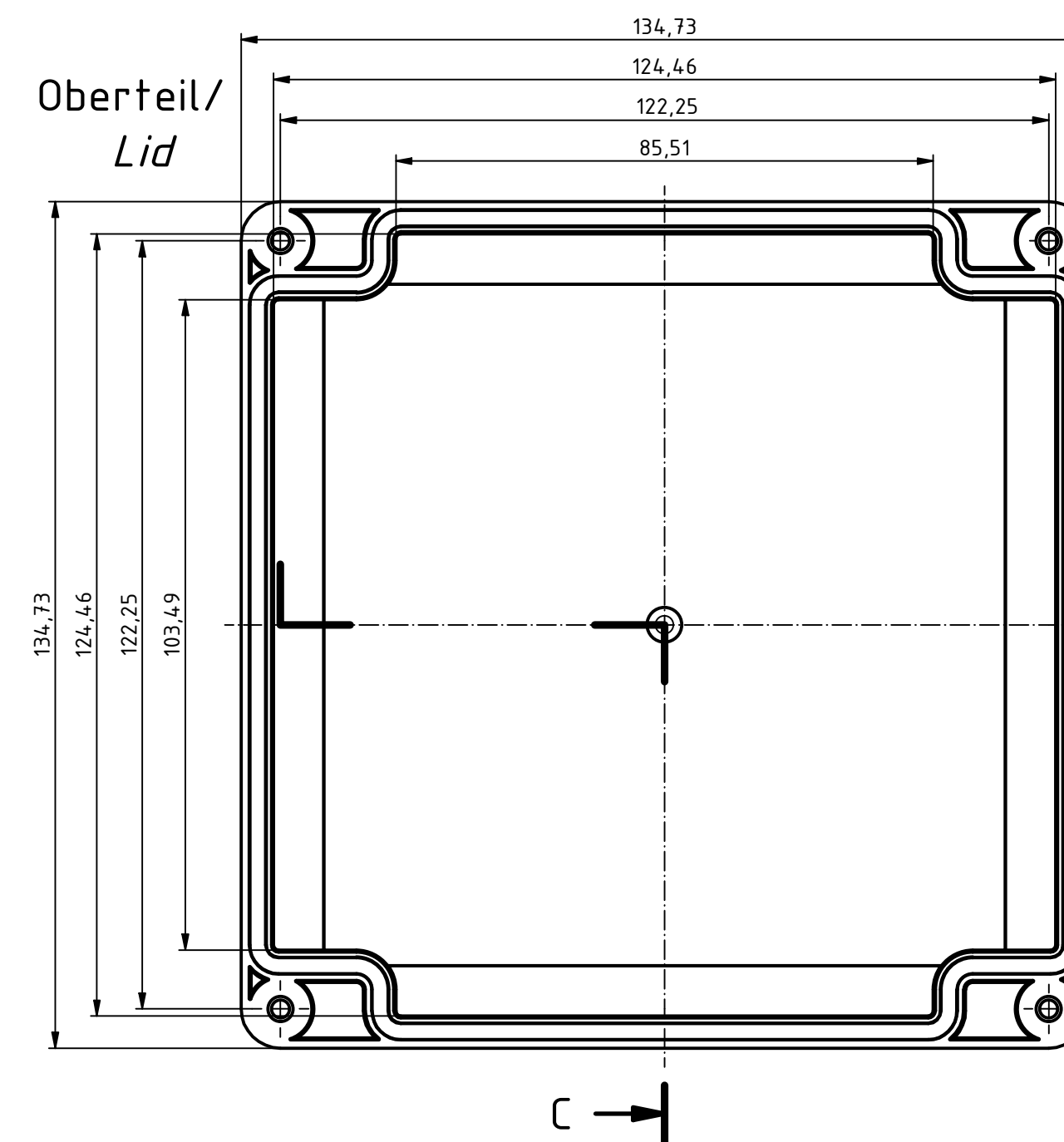
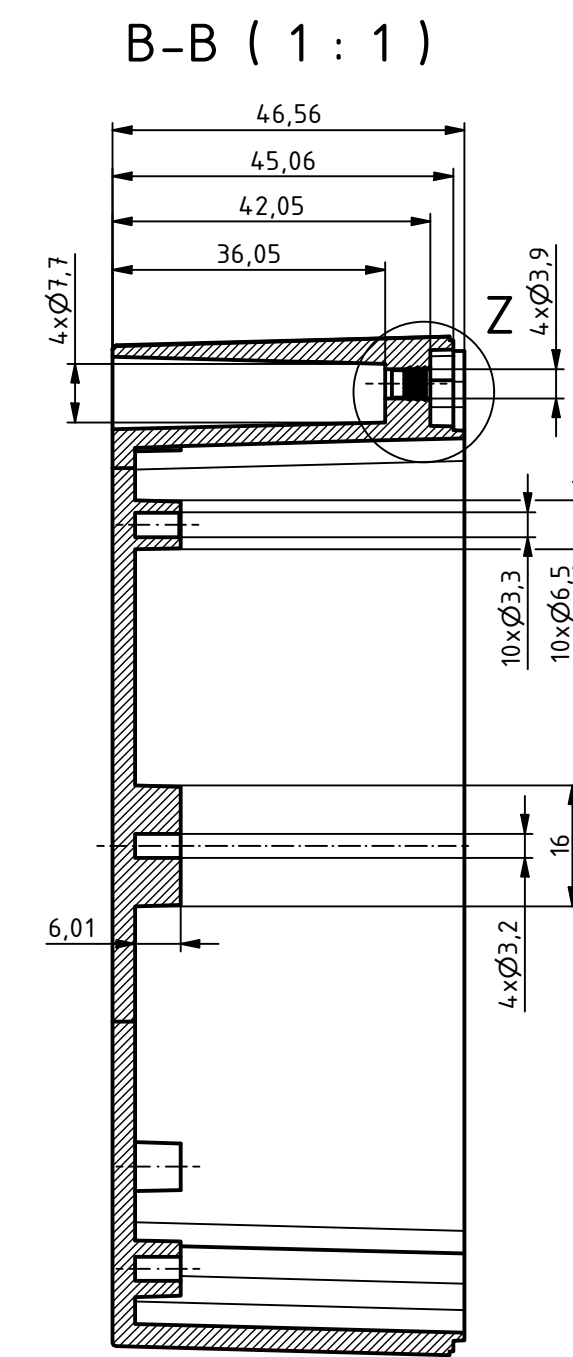


C →

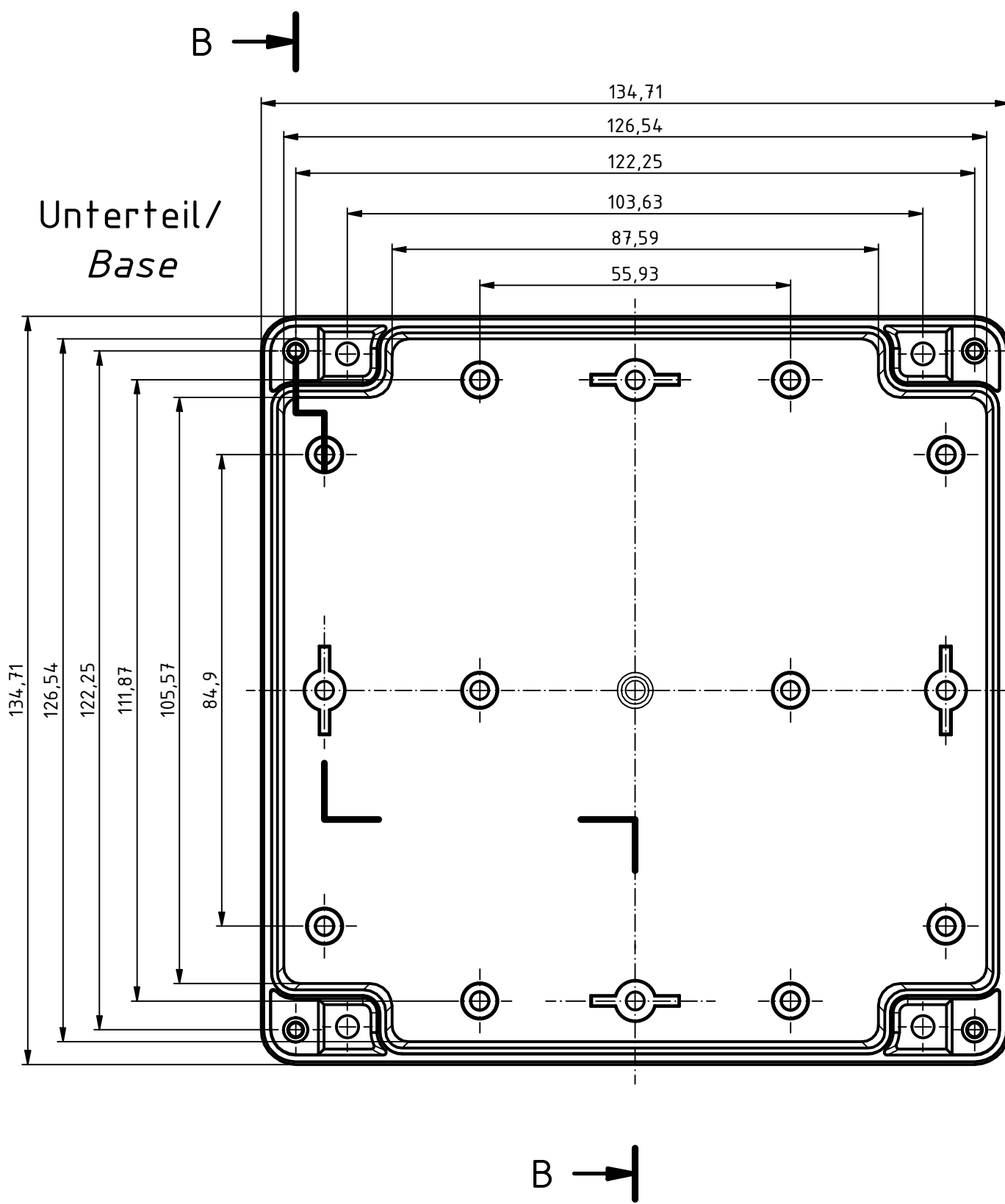


For Version with enclosed gasket
Protection class IP40. To achieve protection class IP65,
the enclosed gasket must be mounted correctly. The gasket must not be stretched
or compressed in the corners. Ends cut obliquely and glued, so that the cut ends
are pressed together by the spring pressure.

Z (2 : 1)

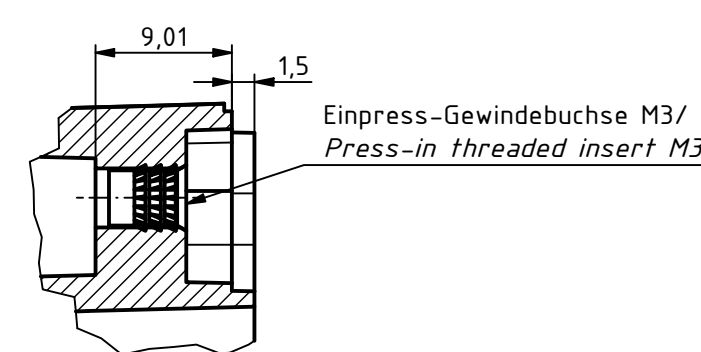

Y (2 : 1)

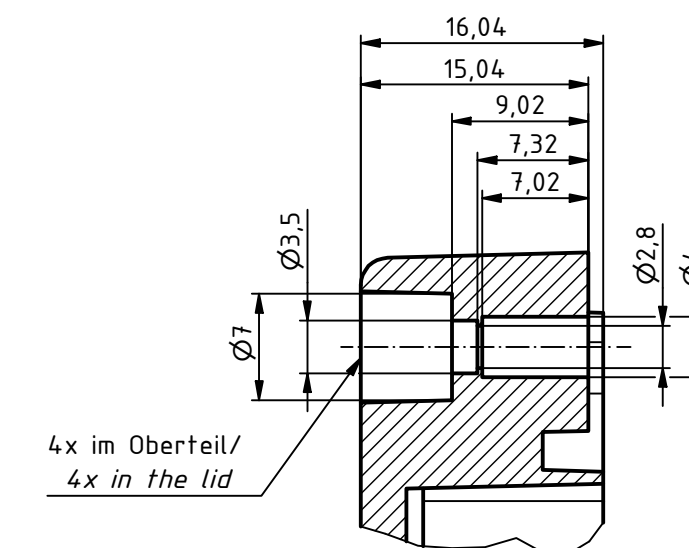

SPECIFICATION	
RND NUMBER	RND 455-01381
Distrelec NUMBER	303-75-325
RND BAR CODE NUMBER	0653415230052
Product text English	Enclosure PC GREY. IP66.68
Outer Dimensions	134.7 x 134.7 x 60.1mm
Inner dimension length	105.6 x 126.5 x 53mm
Material	Polycarbonate
Colour	light grey, similar to RAL 7035
Lid	N/A
Wall brackets	N/A
Colour	light grey, similar to RAL 7035
Protection class	IP66 IP68 IK07