

Blade Receptacles




FEATURES:

Vinyl-insulated
 Female disconnect
 Double crimp
 Funnel entry

SPECIFICATION:

Material	Brass
Insulation material	Vinyl
Surface material	Tin-plated
Temperature range	max. +105 °C

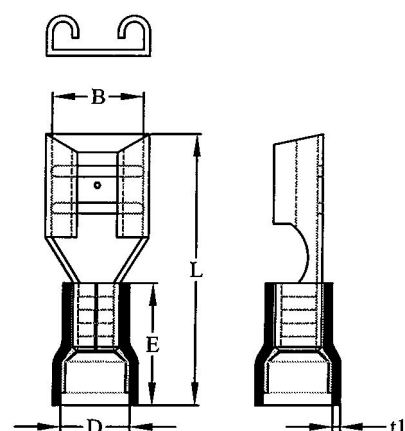

PRODUCT RANGE:

Article Nr.	Colour	Contact	Cross-section	D	L	B	E	t1
RND 465-00501	Red	6.3 x 0.8 mm	0.5...1.5 mm ²	4.3 mm	21.5 mm	6.7 mm	10.5 mm	0.8 mm
RND 465-00502	Red	2.8 x 0.5 mm	0.5...1.5 mm ²	4.3 mm	19 mm	3.2 mm	11 mm	0.8 mm
RND 465-00503	Red	2.8 x 0.8 mm	0.5...1.5 mm ²	4.3 mm	19 mm	3.2 mm	11 mm	0.8 mm
RND 465-00504	Blue	2.8 x 0.5 mm	1.5...2.5 mm ²	4.9 mm	19.5 mm	3.2 mm	11 mm	0.8 mm
RND 465-00505	Blue	2.8 x 0.8 mm	1.5...2.5 mm ²	4.9 mm	19.5 mm	3.2 mm	11 mm	0.8 mm
RND 465-00506	Blue	6.3 x 0.8 mm	1.5...2.5 mm ²	4.9 mm	21.5 mm	6.7 mm	11 mm	0.8 mm
RND 465-00507	Red	4.8 x 0.5 mm	0.5...1.5 mm ²	4.3 mm	19.5 mm	5 mm	10.5 mm	0.8 mm
RND 465-00508	Red	4.8 x 0.8 mm	0.5...1.5 mm ²	4.3 mm	19.5 mm	5 mm	10.5 mm	0.8 mm
RND 465-00509	Blue	4.8 x 0.5 mm	1.5...2.5 mm ²	4.9 mm	20 mm	5 mm	11 mm	0.8 mm
RND 465-00510	Blue	4.8 x 0.8 mm	1.5...2.5 mm ²	4.9 mm	20 mm	5 mm	11 mm	0.8 mm
RND 465-00511	Yellow	4.8 x 0.8 mm	4...6 mm ²	7 mm	23 mm	5 mm	14 mm	0.8 mm
RND 465-00512	Yellow	6.3 x 0.8 mm	4...6 mm ²	7 mm	24 mm	6.7 mm	14 mm	0.8 mm