

Blade Receptacles




FEATURES:

Nylon, fully-insulated
 Female disconnect
 Double crimp
 Funnel entry

SPECIFICATION:

Material	Brass
Insulation material	Nylon
Surface material	Tin-plated
Temperature range	max. +105 °C

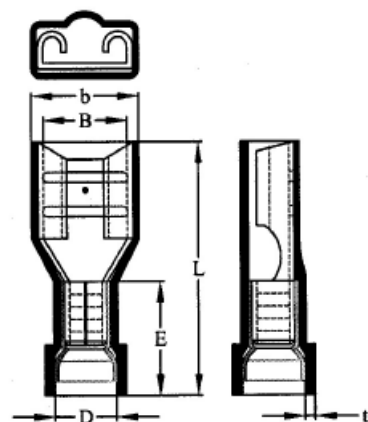

PRODUCT RANGE:

Article Nr.	Colour	Contact	Cross-Section	D	L	Thickness	B	b	E	t1
RND 465-00513	Blue	4.8 x 0.8 mm	1.5...2.5 mm ²	5 mm	20 mm	0.4 mm	5 mm	7.4 mm	10.5 mm	0.8 mm
RND 465-00514	Blue	6.3 x 0.8 mm	1.5...2.5 mm ²	5 mm	22 mm	0.4 mm	6.7 mm	9 mm	11 mm	0.8 mm
RND 465-00515	Red	2.8 x 0.5 mm	0.5...1.5 mm ²	4.3 mm	19 mm	0.25 mm	3.2 mm	5.9 mm	10.5 mm	0.8 mm
RND 465-00516	Red	2.8 x 0.8 mm	0.5...1.5 mm ²	4.3 mm	19 mm	0.25 mm	3.2 mm	5.9 mm	10.5 mm	0.8 mm
RND 465-00517	Red	4.8 x 0.8 mm	0.5...1.5 mm ²	4.3 mm	19.5 mm	0.4 mm	5 mm	7.4 mm	10.5 mm	0.8 mm
RND 465-00518	Red	6.3 x 0.8 mm	0.5...1.5 mm ²	4.3 mm	21.5 mm	0.4 mm	6.7 mm	9 mm	10.5 mm	0.8 mm
RND 465-00519	Yellow	6.3 x 0.8 mm	4...6 mm ²	6.6 mm	26 mm	0.4 mm	6.7 mm	9 mm	14 mm	0.8 mm