


# Butt Splice Connectors

## Non-Insulated



### SPECIFICATION:

Material	Copper
Surface material	Tin-plated
Colour	Metallic

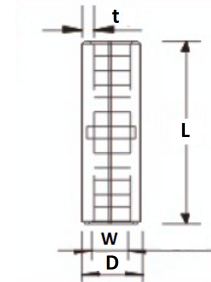

### PRODUCT RANGE:

Article Nr.	Cross-section	AWG	Colour	D	L	t	W
RND 465-00577	4...6 mm <sup>2</sup>	12-10 AWG	Metallic	5.52 mm	15 mm	0.95 mm	3.6 mm
RND 465-00578	0.5...1.5 mm <sup>2</sup>	22-16 AWG	Metallic	3.32 mm	15 mm	0.75 mm	1.85 mm
RND 465-00579	1.5...2.5 mm <sup>2</sup>	16-14 AWG	Metallic	4.02 mm	15 mm	0.8 mm	2.5 mm
RND 465-00580	8 mm <sup>2</sup>	8 AWG	Metallic	7 mm	21 mm	1.25 mm	4.5 mm
RND 465-00675	14 mm <sup>2</sup>	6 AWG	Metallic	9 mm	27.5 mm	1.3 mm	6.4 mm
RND 465-00676	22 mm <sup>2</sup>	4 AWG	Metallic	11.3 mm	30.5 mm	1.5 mm	8.2 mm