

Crimp terminal, socket




FEATURES:

Nylon fully-insulated

Double crimp

SPECIFICATION:

Material	Brass
Insulation material	Nylon
Surface material	Tin-plated
Temperature range	max. +105 °C

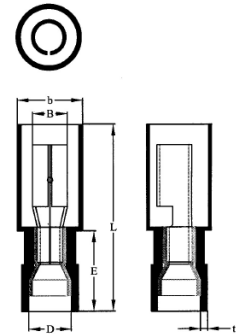

Article Nr.	AWG	Contact	Colour	D	L	B	t	b	E	t1
RND 465-00585	22-16 AWG	0.5...1.5 mm ²	Red	4.3 mm	24 mm	4.65 mm	0.4 mm	7 mm	10.5 mm	0.75 mm
RND 465-00586	16-14 AWG	1.5...2.5 mm ²	Blue	5 mm	24 mm	4.65 mm	0.4 mm	7.9 mm	10.5 mm	0.8 mm
RND 465-00587	16-14 AWG	1.5...2.5 mm ²	Blue	5 mm	24 mm	5.65 mm	0.4 mm	7.9 mm	10.5 mm	0.8 mm
RND 465-00596	12-10 AWG	4...6 mm ²	Yellow	6.6 mm	27 mm	4.65 mm	0.4 mm	7.9 mm	13 mm	0.8 mm