


# Crimp Terminal, Socket



## FEATURES:

- Fully-insulated nylon receptacles
- Double crimp
- Funnel entry
- Coated with hot-melt adhesive on the inside

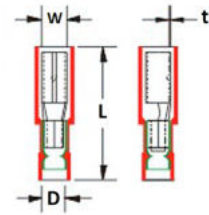

## SPECIFICATION:

Material	Brass
Insulation material	Nylon
Surface material	Tin-plated
Temperature range	max. +105 °C

Article Nr.	AWG	Contact	Colour	D	L	W	t
RND 465-00588	22-16 AWG	0.5...1.5 mm <sup>2</sup>	Red	4.3 mm	40.2 mm	4.65 mm	0.4 mm
RND 465-00589	16-14 AWG	1.5...2.5 mm <sup>2</sup>	Blue	5 mm	42.5 mm	4.65 mm	0.4 mm