

# Piggyback Terminal




## FEATURES:

Vinyl insulated  
Double crimp  
PVC  
Funnel entry

## SPECIFICATION:

Material	Brass
Insulation material	Vinyl
Surface material	Tin-plated
Temperature range	max. +105 °C
Thickness	0.4 mm

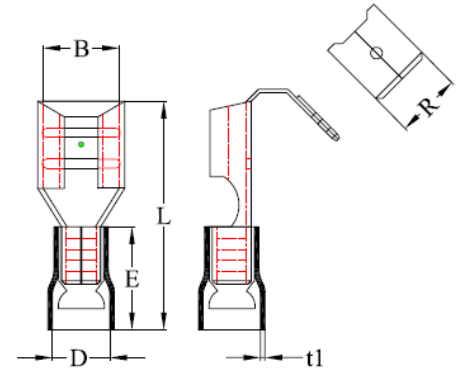

Article Nr.	Tab Size	AWG	Contact	Colour	D	L	B	R	t1	E
RND 465-00602	6.3 x 0.8 mm	22-16 AWG	0.5...1.5 mm <sup>2</sup>	Red	4.3 mm	22.5 mm	6.7 mm	6.2 mm	0.8 mm	10.5 mm
RND 465-00603	6.3 x 0.8 mm	12-10 AWG	4...6 mm <sup>2</sup>	Yellow	6.5 mm	26 mm	6.7 mm	6.2 mm	0.8 mm	14 mm
RND 465-00604	6.3 x 0.8 mm	16-14 AWG	1.5...2.5 mm <sup>2</sup>	Blue	4.9 mm	23 mm	6.7 mm	6.2 mm	0.8 mm	11 mm