

Ring Cable Lugs




FEATURES:

Non-insulated ring terminals

SPECIFICATION:

Material	Copper
Surface material	Tin-plated

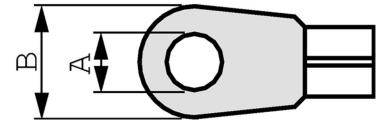

PRODUCT RANGE:

Article Nr.	Cross-section	AWG	A	B	Length	Thickness	Stud Size
RND 465-00608	1.5...2.5 mm ²	16-14 AWG	4.3 mm	6.6 mm	14.4 mm	0.8 mm	#8
RND 465-00609	0.2...0.5 mm ²	22-20 AWG	3.2 mm	5.2 mm	12.4 mm	0.5 mm	#2
RND 465-00610	0.5...1.5 mm ²	22-16 AWG	3.2 mm	5.5 mm	11.5 mm	0.7 mm	#4
RND 465-00611	0.5...1.5 mm ²	22-16 AWG	4.3 mm	8 mm	15.8 mm	0.7 mm	#8
RND 465-00612	1.5...2.5 mm ²	16-14 AWG	5.3 mm	8.5 mm	16.8 mm	0.8 mm	#10
RND 465-00613	1.5...2.5 mm ²	16-14 AWG	6.4 mm	12 mm	21.2 mm	0.8 mm	1/4
RND 465-00614	4...6 mm ²	12-10 AWG	6.4 mm	12 mm	25.5 mm	1 mm	1/4
RND 465-00618	8 mm ²	8 AWG	8.6 mm	15 mm	29.6 mm	1.2 mm	5/16
RND 465-00619	8 mm ²	8 AWG	10.7 mm	15 mm	29.6 mm	1.2 mm	3/8
RND 465-00620	14 mm ²	6 AWG	6.6 mm	12 mm	29.5 mm	1.1 mm	1/4
RND 465-00621	14 mm ²	6 AWG	8.6 mm	16 mm	32.8 mm	1.5 mm	5/16
RND 465-00622	14 mm ²	6 AWG	10.7 mm	16 mm	32.8 mm	1.5 mm	3/8
RND 465-00623	22 mm ²	4 AWG	6.6 mm	12 mm	30.9 mm	1.8 mm	1/4
RND 465-00677	8 mm ²	8 AWG	6.6 mm	12 mm	23.8 mm	1.2 mm	1/4
RND 465-00678	22 mm ²	4 AWG	8.6 mm	16.5 mm	33.15 mm	1.8 mm	5/16
RND 465-00679	22 mm ²	4 AWG	10.7 mm	17.5 mm	35.95 mm	1.8 mm	3/8