

# Heat-Shrinkable Blade Receptacles




## FEATURES:

Heat shrink insulated female disconnects  
 Funnel entry  
 Coated with hot-melt adhesive on the inside

## SPECIFICATION:

Material	Brass
Surface material	Tin-plated
Max. temperature	+105 °C

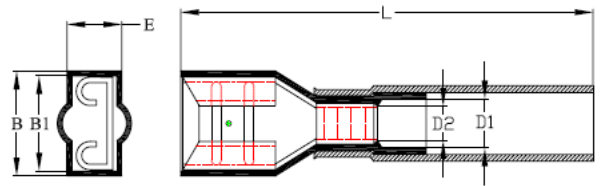

Article Nr.	Cross-section	AWG	Contact	Colour	D1	L	B1	B	D2	E
RND 465-00669	0.5...1.5 mm <sup>2</sup>	22-16 AWG	6.3 x 0.8 mm	Red	4.4 mm	38.5 mm	8.2 mm	9.4 mm	1.7 mm	4.4 mm
RND 465-00670	1.5...2.5 mm <sup>2</sup>	16-14 AWG	6.3 x 0.8 mm	Blue	4.4 mm	38.5 mm	8.2 mm	9.4 mm	2.3 mm	4.4 mm
RND 465-00671	4...6 mm <sup>2</sup>	12-10 AWG	6.3 x 0.8 mm	Yellow	6.65 mm	40 mm	8.1 mm	9.4 mm	3.4 mm	5 mm